

## ToLEDo Ball

*ToLEDo Ball Dim Frosted 250LM E27 SL*

**0026943**



### Range features

- Up to 80% energy saving compared to incandescent lamps
- Instant light
- Suitable for replacement for 25W and 40W incandescent lamps
- Available in Homelight (2700K)
- Good colour rendering (CRI 80+)
- Average rated life 25,000 hrs



### PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026943
Average life (Rated) (h)	25000
Energy class	A+
Lamp shape	Ball
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	E27
Type	ToLEDo Ball
EAN code	5410288269436
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Watt (Nominal) (W)	4.5
Equivalent watt (W)	25
Voltage (V)	220-240

## ToLEDo Ball

ToLEDo Ball Dim Frosted 250LM E27 SL

0026943

### DATA TABLE

#### General data

Ordering number	0026943
Dry applications use only	Yes
Technology	LED
Energy saving lamp	Yes
Energy class	A+
Average life (Rated) (h)	25000
Average life (Nominal) (h)	25000
Lamp finish	Frosted
Lamp shape	Ball
Dimmable	Yes
Cap/Base	E27
Type	ToLEDo Ball
EAN code	5410288269436
E-number FI	4740199
Long description	Up to 80% energy saving compared to incandescent lamps. Instant light. Suitable for replacement for 25W and 40W incandescent lamps. Available in Homelight (2700K). Good colour rendering (CRI 80+). Average rated life 25,000 hrs
Product name	ToLEDo Ball Dim Frosted 250LM E27 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	50000
Special purpose lamp	No
Sales pack quantity	6
Optimal operating condition (°C)	25

#### Optical data

Light colour	Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	250

## ToLEDo Ball

*ToLEDo Ball Dim Frosted 250LM E27 SL*

**0026943**

### Electrical data

<b>kWh per 1000 hours burning time</b>	5
<b>Equivalent watt (W)</b>	25
<b>Watt (Rated) (W)</b>	4.5
<b>Watt (Nominal) (W)</b>	4.5
<b>Voltage (V)</b>	220-240
<b>Current (A)</b>	0.024
<b>Lamp power factor</b>	0.55

### Physical data

<b>Weight (kg)</b>	0.06
<b>Lamp Length (mm) - C/L</b>	87
<b>Max. Lamp Diameter (mm) - D</b>	45
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	10.20 x 4.80 x 4.80
<b>Inner package dimensions (L x W x H) (cm)</b>	15.50 x 10.50 x 11.70
<b>Inner package net weight (kg)</b>	0.36
<b>Outer package dimensions (L x W x H) (cm)</b>	55.00 x 32.60 x 13.70


## ToLEDo Ball

*ToLEDo Ball Dim Frosted 250LM E27 SL*

**0026943**

### TECHNICAL DRAWINGS

---

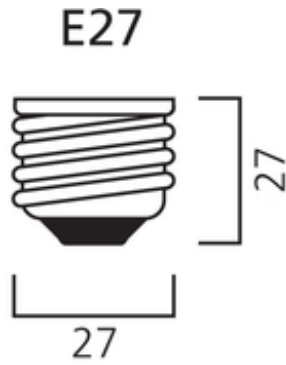

### ENERGY LABEL

---

□