


Datasheet

RS 2.54mm 72 Way 2 Row Right Angle PCB Socket Through Hole Socket Strip

RS Stock number [488-1746](#)

Dimensions: mm

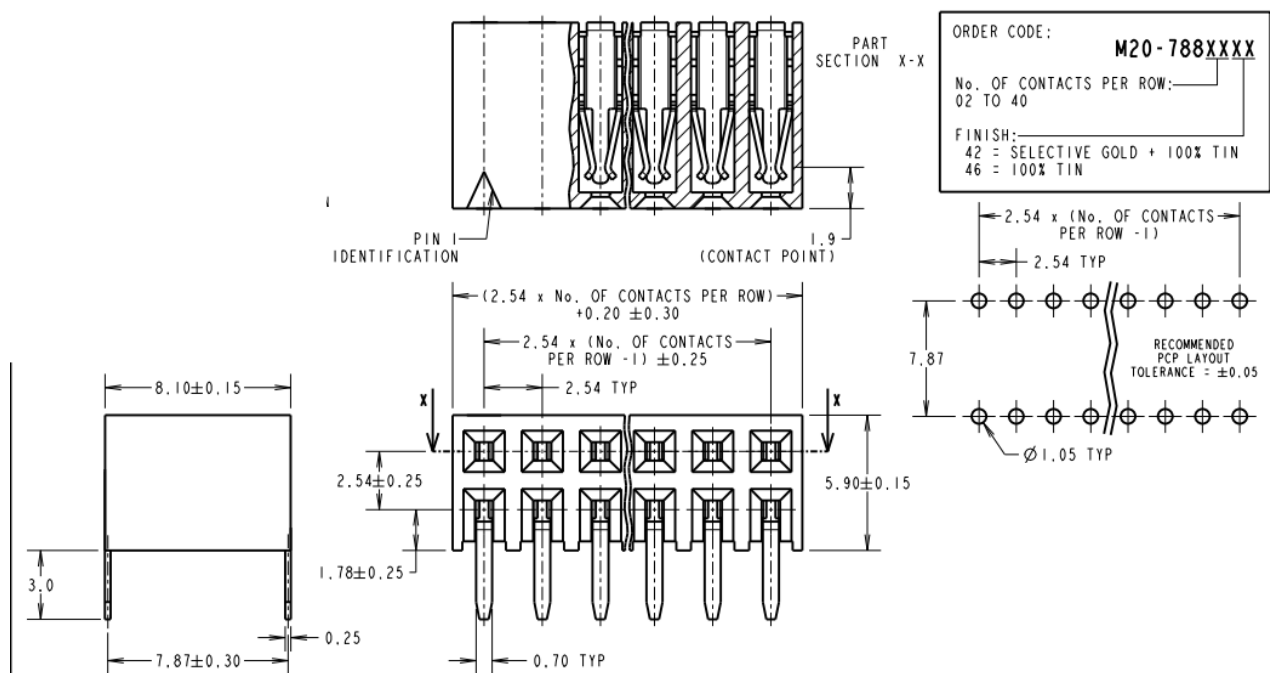

Specifications

Material

Moulding: PA6T, UL94V-0, Black
 Contacts: Phosphor bronze

Finish

Nickel all over, gold on contact area
 100% tin on tails
 100% tin over nickel

Electrical

Current rating: 3A
 Voltage proof: 1000V AC
 Contact resistance: 20mΩmin

Environmental

Temperature range: 40 °C to +105 °C

Mechanical

Insertion force: 1.96N max
 Withdrawal force: 0.29N min
 Durability: 300 operations

Packing

Tube