
LIGHTIFY Surface Light TW

LIGHTIFY Surface Light TW | Indoor LED ceiling and wall luminaires with LIGHTIFY technology, color temperature adjustable



Product benefits

- Controllable via smart devices (via Android and iOS)
- Complete LIGHTIFY function
- Easy to install and use
- Contains no mercury

Product features

- Extremely low profile LED ceiling and wall luminaire with smart lighting function
- Adjustable color temperature via Tunable White: 2,700 K...6,500 K
- Dimmable via LIGHTIFY



Technical data

Electrical data

Nominal wattage	28 W
Nominal voltage	230 V
Mains frequency	50/60 Hz


Photometrical data

Color temperature	2700...6500 K
Luminous flux	70 lm

Light technical data

Light color management	Adjustable color temperature
------------------------	------------------------------

Dimensions & weight

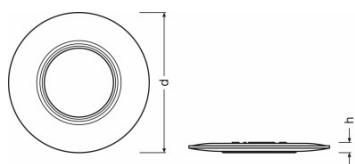

Diameter	380.0 mm
Height	23.0 mm

Additional product data

Number of lighting outlets	36x 2
----------------------------	-------

Capabilities

LIGHTIFY technology	Yes
---------------------	-----

Certificates & standards

Luminous efficacy of lamp in luminaire	107 lm/W
Type of protection	IP20

Country specific categorizations

Product datasheet

Order reference	LIGHTIFY SURFAC
------------------------	-----------------

Equipment / Accessories

- LIGHTIFY APP required
- LIGHTIFY Gateway required

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899926158	LIGHTIFY Surface Light TW	Shipping carton box 2	439 mm x 430 mm x 142 mm	26.81 dm ³	4194.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.