

# Power connectors - VS-PPC-C2-MSTB-POBK-P13-A5-SP - 1657892


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Connector MSTB, IP67, with push-pull interlocking, plastic housing, 24 V, 5-polig, with spring-cage connection, for AWG 18 ... 13, for cable cross section 9.0 mm ... 13.0 mm



## Key commercial data

Packing unit	1 pc
GTIN	 4 046356 131964
Weight per Piece (excluding packing)	43.7 g
Custom tariff number	85366990
Country of origin	Germany

## Technical data

### Mechanical characteristics

Number of positions	5
Connection profile	MSTB
Locking type	Push Pull
Insertion/withdrawal cycles	≥ 100
Connection method	Spring-cage connection
Conductor cross section	0.75 mm <sup>2</sup> ... 2.5 mm <sup>2</sup>
Connection cross section AWG	18 ... 13
External cable diameter	9 mm ... 13 mm
Cable exit	Straight
Color	black

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
Degree of protection	IP65/67

### Material data

Inflammability class according to UL 94	V0
Housing material	PA-GF

# Power connectors - VS-PPC-C2-MSTB-POBK-P13-A5-SP - 1657892

## Technical data

### Material data

Contact carrier material	PA
Contact material	Copper alloy
Contact surface material	Gold over nickel
Material	Plastic
Sealing material	NBR
Seal material	NBR
Cable seal material	TPE

### Electrical characteristics

Number of positions	5
Rated current	16 A (at 20 °C)
Pollution degree	2

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260703
eCl@ss 7.0	27440101
eCl@ss 8.0	27440101

### ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC002636
ETIM 5.0	EC002636

### UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

## Approvals

### Approvals

#### Approvals

UL Recognized / cUL Recognized / GOST / GOST / cULus Recognized

# Power connectors - VS-PPC-C2-MSTB-POBK-P13-A5-SP - 1657892

## Approvals

Ex Approvals

Approvals submitted

## Approval details

UL Recognized	
mm <sup>2</sup> /AWG/kcmil	14
Nominal current I <sub>N</sub>	16 A
Nominal voltage U <sub>N</sub>	24 V

cUL Recognized	
mm <sup>2</sup> /AWG/kcmil	14
Nominal current I <sub>N</sub>	16 A
Nominal voltage U <sub>N</sub>	24 V

GOST

GOST

cULus Recognized

## Accessories

Accessories

Connector

# Power connectors - VS-PPC-C2-MSTB-POBK-P13-A5-SP - 1657892

## Accessories

Ferrule - AI 1,5 -10 BK - 3200195



Ferrule, Sleeve length: 10 mm, Length: 18 mm, Color: black

 
Ferrule - AI 2,5 -10 BU - 3202533



Ferrule, Sleeve length: 10 mm, Length: 17 mm, Color: blue


## Drawings

Schematic diagram



Connector pin assignment for PROFINET  
Push-Pull, power connector, 24 V

Dimensioned drawing

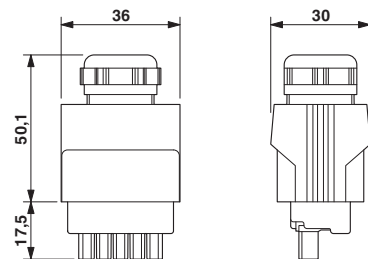

Push-Pull MSTB connector IP65/67