

EC-Aura

Stand alone, wheel mounted EC fan


The EC Aura is a quiet yet powerful portable fan. Designed with a variable speed controller, the air flow can be varied to offer gentle cooling to high powered blowing. These fans provide an adjustable, energy efficient, low noise option to traditional temporary cooling solutions.



- Infinitely variable speed control
- Available in 230VAC & 110VAC 50/60Hz versions
- 180° adjustable tilt angle
- ebm-papst GreenTech energy efficient EC fan
- Robust Polyethylene moulding
- Rubber wheels and convenient handle for easy positioning
- Extrusion coated polypropylene impellor
- Heavy duty powder-coated wheeled frame for effortless positioning
- Maintenance-free IP54 Motor
- 230V supplied with adjustable EU and standard UK 3-pin
- 115V supplied with a 3-pole Pin & Sleeve Connector (16 A)

	Supply Voltage	Frequency	Maximum airflow	Max. Current Draw	Max. power input	Sound Pressure @ 3M	Mass	Max. Ambient Temperature	Air Velocity @ 5M	Air Velocity @ 10M	Air Velocity @ 15M	Air Velocity @ 20M
Part Number	VAC	Hz	m ³ /h	Amps	kW	dB(A)	kg	°C	m ³ /s	m ³ /s	m ³ /s	m ³ /s
Cool500ec-230	230	50/60	7250	2.2	0.36	67	24	+55	2.3	1.3	1.1	1.0
Cool500ec-115	115	50/60	7250	3.3	0.37	67	24	+55	2.3	1.3	1.1	1.0

Dimensions

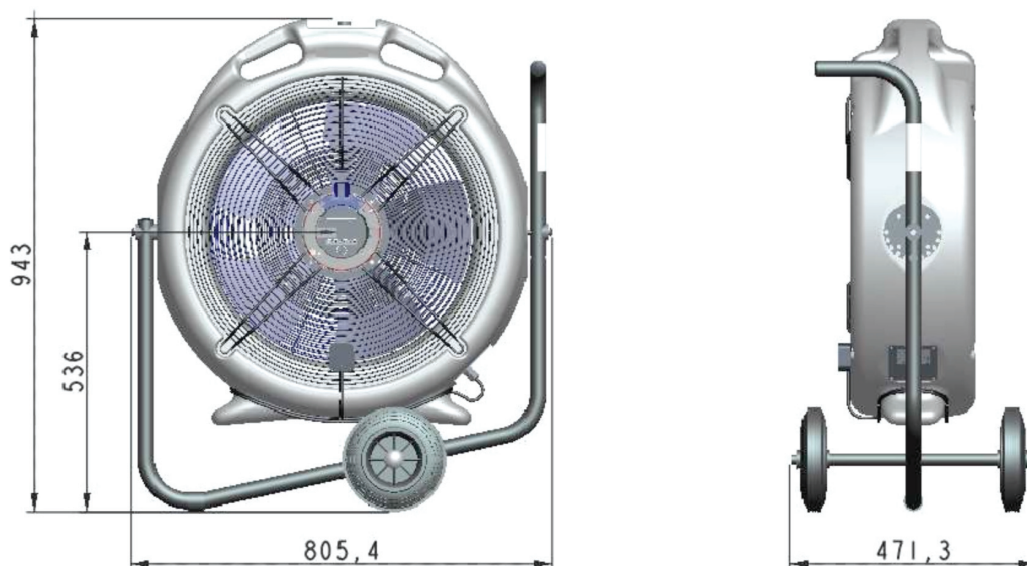

Standards:
The ec aura range is RoHS compliant and CE marked.

