


Capacitor, ceramic, 4.7 uF, +/-10% Tol, 25 V, X7R, Lead Spacing=0.4"

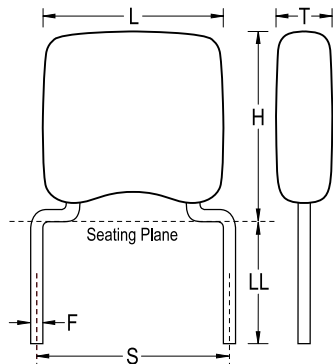

General Information	
Supplier:	KEMET
Application:	General Purpose
Temperature Coefficient:	X7R
Body Type:	Radial Conformal
Lead Type:	Wire Leads
Termination Type:	Tin (Sn)
RoHS:	Yes

Dimensions (in)		
Symbol	Dimension	Tolerance
L	0.33	MAX
H	0.32	MAX
T	0.2	MAX
S	0.4	NOM
LL	0.276	MIN
F	0.025	NOM

Specifications	
Capacitance:	4.7 uF
Voltage:	25 V
Tolerance:	+/-10%
Temperature Range:	-55/+125C
Failure Rate:	NA
Dissipation Factor:	3.5%
Insulation Resistance:	110 MOhm
Dielectric Strength:	62.5 V

Packaging Specifications	
Package Kind:	Bulk
Package Type:	Bag
Package Quantity:	50