


Plateswitches

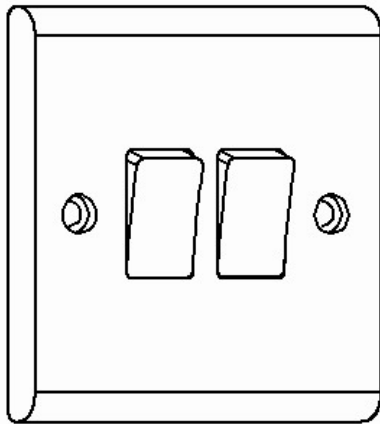

Description

This uniquely shaped range is easy to install, has clear white terminal markings and is supplied in individual protective bags.

This range of plateswitches do not have to be de-rated for fluorescent loads.

Features

- unique slim profile with curved top and bottom edges
- concave rockers
- only one size 4mm screwdriver needed
- clear white markings
- grey font engraving
- terminals have large lead-ins
- range can be expanded using Gridswitch range
- 25 year guarantee

Range

1g 1w	S1202
1g 2w	S1203
2g 2w	S1204
3g 2w	S1205
4g 2w	S1244
6g 2w	S1245
Intermediate	S1246
3 pole fan isolator	S1247
Push to make/break 2w 'press'	S1249
Push to make/break 2w – bell symbol	S1249B
Door card switch, energy saving	S1248

Technical Specification

voltage rating	250Vac
current rating	10A
	X rated
contact gap	3mm

no user serviceable parts

Back Boxes

minimum recommended depth

	flush	dry lining 35mm	surface
1-3g	DB152	DB2540	V1220/E
4-6g	DB163	DB2541	V1223

Standards

- BS EN 60669-1:2000

Terminal Capacity

	1mm ²	1.5mm ²	2.5mm ²	4mm ²
L	5	4	2	1

DETA

Kingsway House, Laporte Way
 Luton, Beds LU4 8RJ
 Tel. +44 1582 544 500 Fax: +44 1582 544 501
 Technical Helpline +44 1582 544 548