

Datasheet

RS PRO UY2 Wire Connector, Low Voltage Products, Max. Voltage 36V

Stock number: 239-3988




Specifications:

UY2 wire connector designed for 0.4mm-0.9mm(26-19AWG) copper or copper-clad steel connector with insulation diameters 2.08mm(0.082").

Features:

UY2 wire connector, two wire inline joints on telephone drop wire of phosphor bronze with plated tin conductors, which will be suitable for crimping tool shown.

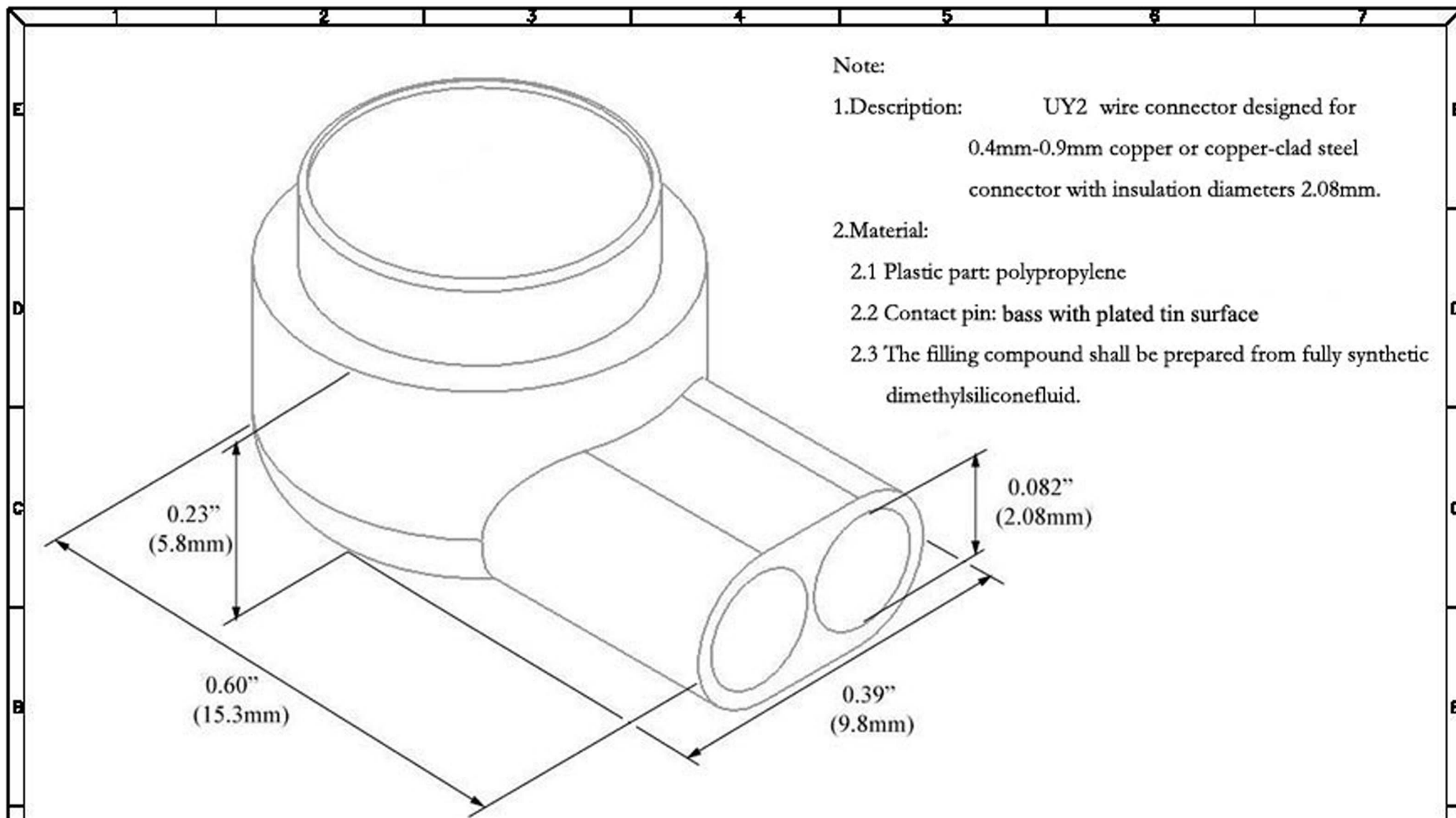

Note:

1. Description: UY2 wire connector designed for 0.4mm-0.9mm copper or copper-clad steel connector with insulation diameters 2.08mm.
2. Material:
 - 2.1 Plastic part: polypropylene
 - 2.2 Contact pin: bass with plated tin surface
 - 2.3 The filling compound shall be prepared from fully synthetic dimethylsiliconefluid.

			Tolerance: X. ± 0.5 X ± 0.3 .XX ± 0.10	SCALE: FREE	Description	UY2 Wire Connector, Low Voltage Products,Max. Voltage 36V.		Approved by Deshen Liu
				UNIT: mm		CUSTOMER P/N:	COMPANY P/N: 239-3988	Checked by Jianhao Yang
00		2008-08-25	Angle: X° $\pm 3^{\circ}$ X° $\pm 1^{\circ}$	REV.: ∞		DWG. No.:	TITLE: WIRE CONNECTOR	Design by Bin Hang
REV.		DATE			SHEET 1/1			