

F10-RGB5050-12-30-IP65 are Low Power RGB IP65 Rated LED Flexible Strips suitable for domestic, commercial and retail internal lighting applications.

- Energy Saving
- Compact strip with SMD LED Technology
- Water Resistant to IP65 level*
- 50k hours working life
- High Reliability
- High Efficiency
- 30 LEDs per metre
- Cuttable every 100mm
- 120° beam angle

Applications



- Accent Lighting
- Cabinet Lighting
- Mood Lighting
- Cove Lighting
- Under Cabinet Lighting
- Bookshelf Lighting
- Display Cabinet Lighting

Low Power RGB IP65 Rated Energy Saving LED Flexi Strip



★ Flexi Strip Specification

Part Number	F10-RGB5050-12-30-IP65
Power	7.2W per metre
Input	12V
LEDs Per Meter	30
Cuttable Length	every 100mm
IP Rating	IP65
Colour	RGB
Lumens	250lm/metre
Length	5 Metres
Weight	250g

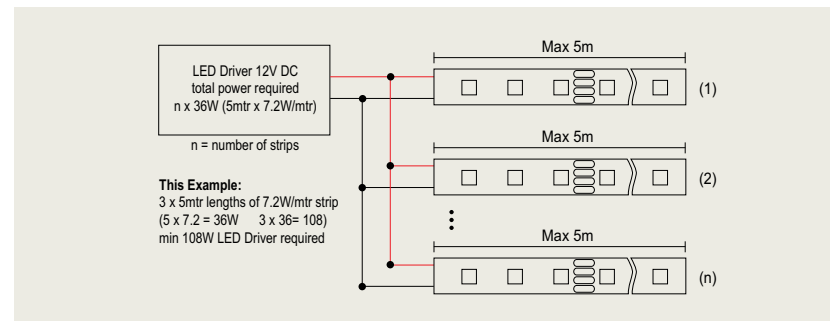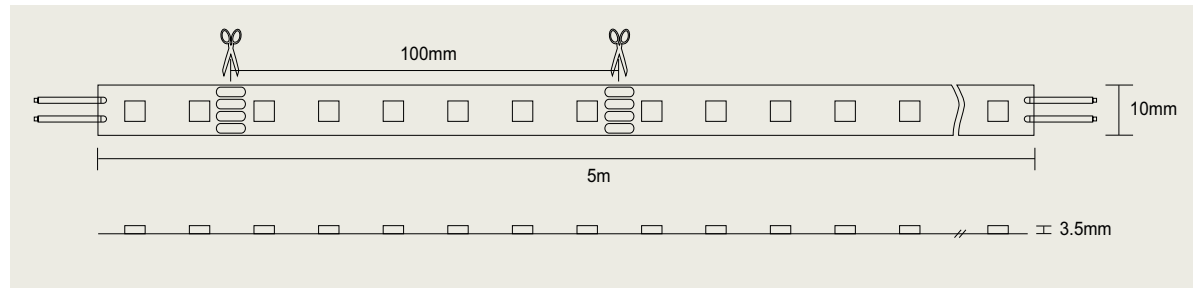

*Product not fully IP65 Rated unless IP65 Rated connections & power supply used
 Representative colours may change; purchase from the same batch code for colour consistency