 


75 - 100 kg

Institutional
Castors
Series 2470



Housing made of pressed steel, zinc-chromatised, double ball bearing swivel head, wheel axle with nut

Wheel: PJO
Wheel centre: Polypropylene
Tread: TENTEprene (thermoplastic rubber) without threadguards, plain bearing

Wheel: YGO electric conductive, non-marking
Wheel centre: Polypropylene
Tread: TENTEprene (thermoplastic rubber) without threadguards, plain bearing




Swivel Castor

- 2470 PJO 075 P30*
- 2470 PJO 100 P30
- 2470 PJO 125 P30
- 2470 PJO 150 P30

		
mm	mm	mm
075	25	11
100	32	11
125	32	11
150	30	11

		
mm	mm	kg
24	100	75
38	135	80
41	160	100
45	185	100

2470 PJO 125 P30

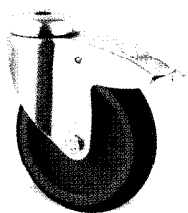

Swivel Castor
with total lock

- 2477 PJO 075 P30*
- 2477 PJO 100 P30
- 2477 PJO 125 P30
- 2477 PJO 150 P30

		
mm	mm	mm
075	25	11
100	32	11
125	32	11
150	30	11

		
mm	mm	kg
24	100	75
43,5	135	80
41	160	100
36	185	100

2477 PJO 125 P30

Castors can be mounted with standard screws; various length screws can be used



Wheel: YGO electric conductive, non-marking
* Wheel Ø 075 mm is also in electric conductive available. Please replace PJO with YGO when ordering.