

Sockets and Plugs, 3-Pole

	2 x 0.5 – 4 mm ² ❶ 250 V/4 kV/3 I _N 25 A	2 x AWG 20 - 12	2 x 0.5 – 4 mm ² ❶ 250 V/4 kV/3 I _N 25 A	2 x AWG 20 - 12
	9 mm / 0.35 in		9 mm / 0.35 in	
	❷ Approvals		❷ Approvals	



Description	Color	Item No.	Pack. Unit	Color	Item No.	Pack. Unit
Connectors, 3-pole, with CAGE CLAMP®S connection	Socket with strain relief housing, for 2 cables, 8 - 11.5 mm diameter ❸			Plug with strain relief housing, for 2 cables, 8 - 11.5 mm diameter ❸		
	● black	770-103	25	● black	770-113	25
	○ white	770-123	25	○ white	770-133	25
Item-Specific Accessories						
	Lockout cap, for sockets, separable, 12-pole			Lockout cap, for plugs, separable, 5-pole		
		black 770-201 100 white 770-221 100			yellow 770-360 100	
				Coding pin, for plugs		
					gray 770-401 100	
770 Series Accessories						
	Locking lever, for "flying leads", manually operated			Locking level, for "flying leads", tool operated		
		black 770-101 100 (4 x 25) white 770-121 100 (4 x 25)			black 770-111 100 (4 x 25) white 770-131 100 (4 x 25)	
Info	Dimensions (in mm)					

- ❶ Conductor sizes: 0.5 - 4 mm² "s + f-st"
0.5 - 2.5 mm² "stranded"
- ❷ "Certification Agencies" and "User Guide"
can be found on pages 176 to 179.
- ❸ For more strain relief housings,
see pages 56 and 57
- black

○ white

● gray

● red

● orange

● brown
- Coding A

Coding A

Coding B

Coding P

Coding R

Coding S
- (L ⊕ N)


(L ⊕ N)

(1 2 3)

(L ⊕ N)

(LON LON S)

(1 2 L)
- For coding information, see pages 164 and 165.
Fire load upon request!

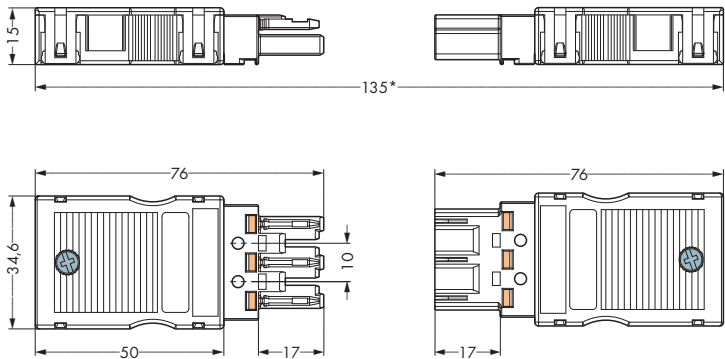

* Overall length when mated