

# Datasheet

## 25m Open Reel

RS Stock number 889-2490




### Description:

Lightweight and sturdy reel, this portable solution delivers for most garden and home improvement situations. It has been designed and engineered for longevity. The plastic drum provides reliable protection when in use, transported or stored. Using highly visible green cable, this range of extension reels provides four shuttered, LED indicator, power switch and has a built-in safety thermal cut-out for protection against overloading when fully reeled.

### Product Information

Part No:	889-2490
Type:	Open Cable Reel
Cable Type:	PVC
Cable Length (m):	25m G.W (kg) 6.5
Amp:	13
Product Dimensions:	H:9.7 x W:8.2 x D:7.8
(Inch/cm)	H:24.7 x W:21 x D:20

## Line Diagram:

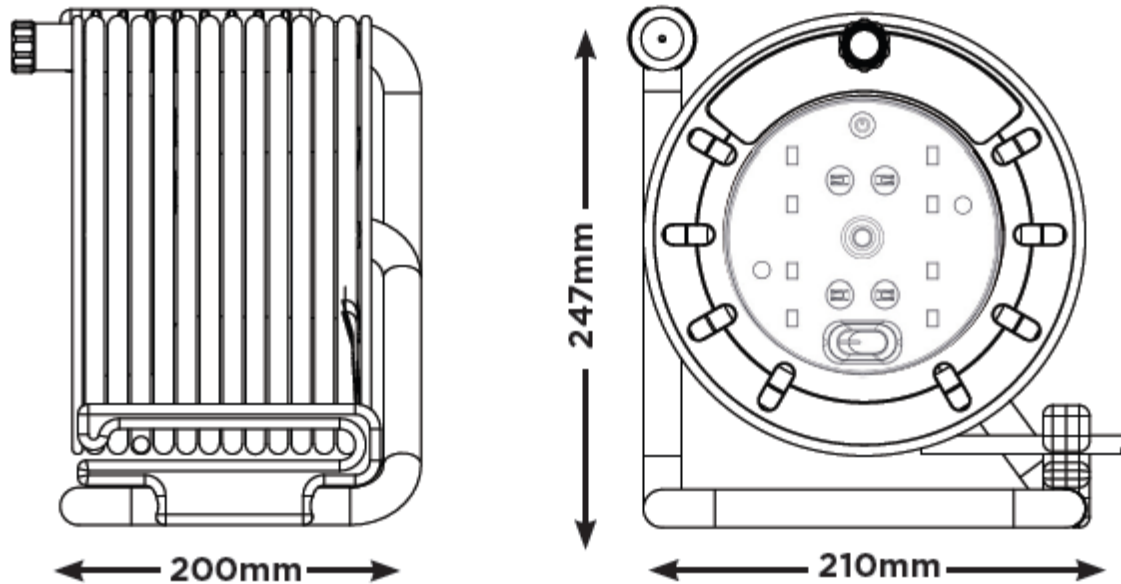

### Features

- » Robust case reel, with four shutter sockets
- » Safety thermal cut-out
- » Power on/off switch
- » Power LED indicator

### Specifications:

Standards:	BS EN 61242. ASTA Approved
Maximum Load:	720W/240V - Fully Wound 3120W/240V - Fully Unwound
Switch:	Double Pole
Cable length:	25m
Cable Size:	Cable Size - 1.25mm <sup>2</sup> (HO5VV-F)