
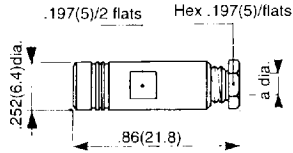


CABLE CLAMP TYPE FOR FLEXIBLE CABLE



STRAIGHT PLUGS

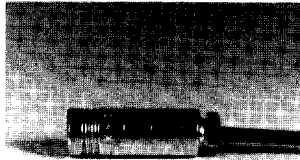

CABLE GROUP	.078 (2) / 50	.102 (2.6) / 50 + 75 S	.150 (3.8) / 95
Part Number (cyl. gasket)	R 114 003 000	R 114 005 000	R 114 009 000
a dia.	.087 (2.2)	.118 (3)	.157 (4)
Assembly	M01 page 16		
Part Number (V groove gasket)	*R 114 003 133	*R 114 005 133	

*For dimensions and assembly instructions ask for the technical data sheet.


RIGHT ANGLE PLUGS

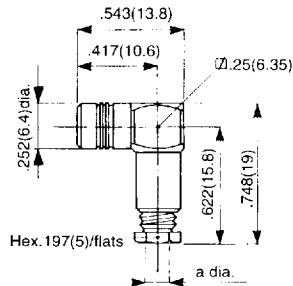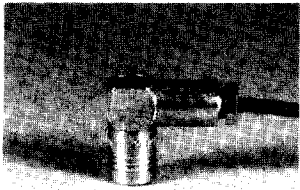

CABLE GROUP	.078 (2) / 50	.102 (2.6) / 50 + 75 S
Part Number (cyl. gasket)	R 114 163 000	R 114 165 000
a dia.	.087 (2.2)	.118 (3)
Assembly	M02 page 17	
Part Number (V groove gasket)	*R 114 163 133	*R 114 165 133

*For dimensions and assembly instructions ask for the technical data sheet.

STRAIGHT JACKS

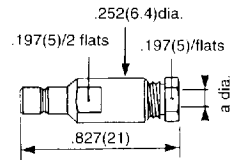


CABLE GROUP	.078 (2) / 50	.102 (2.6) / 50 + 75 S
Part Number (cyl. gasket)	R 114 203 000	R 114 205 000
a dia.	.087 (2.2)	.118 (3)
Assembly	M01 page 16	
Part Number (V groove gasket)	*R 114 203 133•	*R 114 205 133

• Manufactured upon request.

*For dimensions and assembly instructions ask for the technical data sheet.

BULKHEAD STRAIGHT JACKS

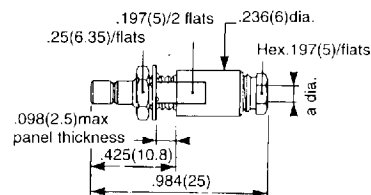

CABLE GROUP	.078 (2) / 50	.102 (2.6) / 50 + 75 S
Part Number (cyl. gasket)	R 114 303 000	R 114 305 000
a dia.	.087 (2.2)	.118 (3)
Assembly	M01 page 16	
Part Number (V groove gasket)	*R 114 303 133	*R 114 305 133
Panel pattern	P01 page 24	

*For dimensions and assembly instructions ask for the technical data sheet.

Standard plating : gold – Available upon request with nickel plating : Please consult us.