


Lampholders for compact fluorescent lamps

26.726.4703

2G11

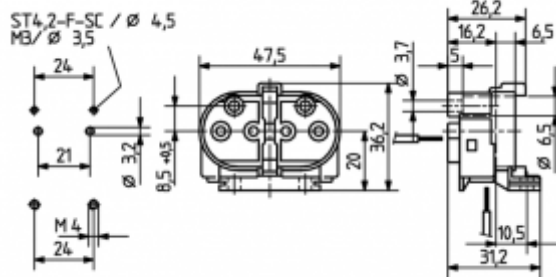

colour	pkg.	wt.	part no.
white	250	20 g	26.726.4703.50

Approval: additional cURus (75W/600V)

For lamps TC-L

Screw fixing vertically

Schraubbefestigung horizontal

Housing: PBT

- Screw fixing horizontally holes: \varnothing 4.3 mm for screws ISO 1207 - M4
- Screw fixing vertically holes: \varnothing 3.7 mm for screws ISO 1207 - M3 or for self-tapping screws with locating groove ISO 1481 - ST 4.2 - F / ISO 4753 - SC, holes: \varnothing 2.4 mm for self-tapping screws with locating groove 1481 - ST 2.9 - F / ISO 4753 - SC
- Can be wired from two sides
- For cable insertion direction please refer to drawing

T 140	U out 500 V		 18 AWG 0.5 - 1.0 mm ²
-------	----------------	--	---