


IP55 Steel Wall Boxes with Removable Door

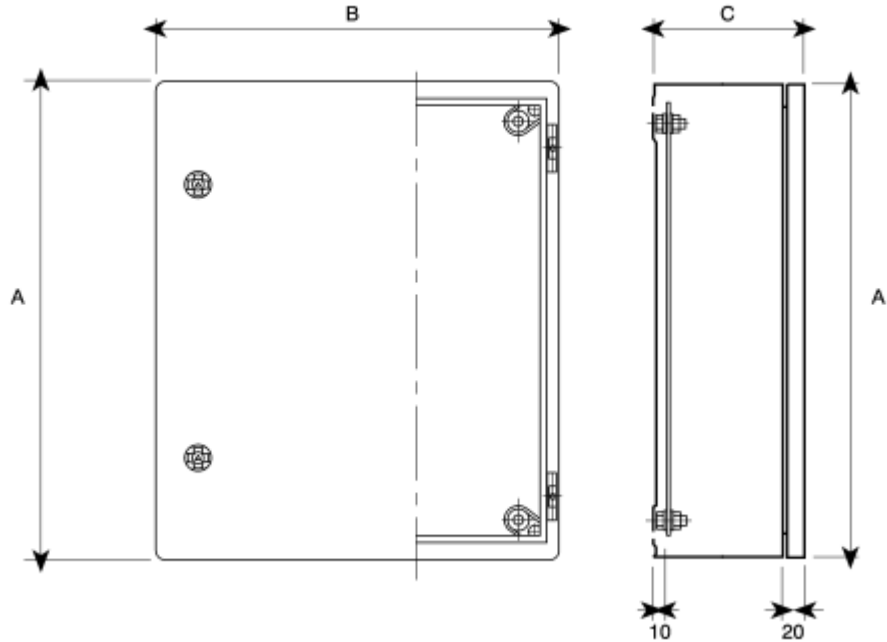

Enclosure Material: Mild steel

Thickness: 1.2 mm

Colour: Light grey (RAL 7035)

Surface Finish: Textured Epoxy Powder

Ingress protection: IP55

Wall Box	External Height (A)	External Width (B)	External Depth (C)	Internal Height	Internal Width	Internal Depth	Chassis Plate
728-6778	250	200	150	247.6	197.6	147.6	208-3748
728-6769	300	300	200	297.6	297.6	197.6	-
728-6807	300	400	150	297.6	397.6	147.6	728-6762
728-6771	400	300	200	397.6	297.6	197.6	728-6762
728-6775	400	400	200	397.6	397.6	197.6	207-7456
728-6784	500	300	200	497.6	297.6	197.6	207-7462
728-6787	500	400	200	497.6	397.6	197.6	207-7478
728-6781	500	500	250	497.6	497.6	247.6	207-7484
728-6790	600	400	250	597.6	397.6	247.6	728-6765
728-6793	600	600	250	597.6	597.6	247.6	-
728-6797	700	500	250	697.6	497.6	247.6	207-7513

Note: dimensions in mm