

11 02 160


Insulation Stripper



- For single, multiple and fine stranded conductors with plastic or rubber insulation up to 5.0 mm dia. or 10 mm² cable cross-section
- Easy adjustment to the required diameter of solid or stranded wire with knurled screw and lock nut
- Special tool steel, forged, oil-hardened



| | |
|--|----------------------------|
| Article No. | 11 02 160 |
| EAN | 4003773010715 |
| Head | polished |
| Handles | with multi-component grips |
| Style | 0 |
| Pliers | black atramentized |
| Stripping capacities in square millimetres mm² | 10,0 |
| Stripping capacities (diameter) Ø mm | 5,0 |
| AWG | 7 |
| Length mm | 160 |
| Net weight g | 165 |

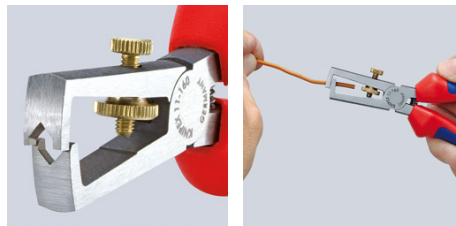

technical change and errors excepted



Spare Parts

| | | |
|--------------------|---------------|---|
| Article No. | EAN | |
| 11 09 01 | 4003773052326 | Set of spare parts (screw and nut) for 11 160 |