



Angular contact ball bearings, double row

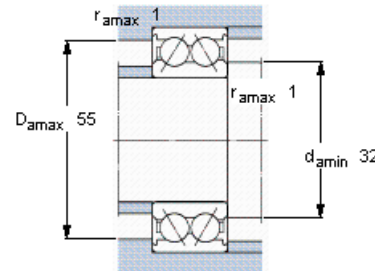

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
25	62	25,4	32	20,4	0,865	11000	11000	0,35	3305 ATN9 *

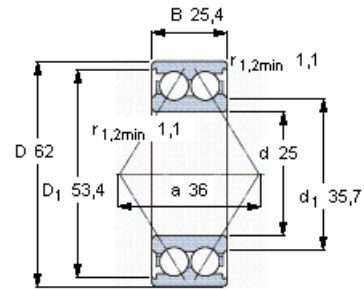

Calculation factors

k_r 0,07
 e 0,8
 X 0,63
 Y_1 0,78
 Y_2 1,24
 Y_0 0,66 Y_0 0,66