





















## Datasheet

# Red Panel Mount Female 3P+E Straight Industrial Power Socket Rated At 16A, 380 → 415 V

RS Stock number [464-1649](#)






### Straight 75


Description		Colour	Pack qty.	Cat. no.
2P+⊕	4h 50/60Hz 100-130V		10/100	• <b>422.1660</b>
	6h 50/60Hz 200-250V		10/100	• <b>422.1663</b>
	9h 50/60Hz 380-415V		10/100	• <b>422.1668</b>
16A 3P+⊕	4h 50/60Hz 100-130V		10/100	• <b>422.1661</b>
	9h 50/60Hz 200-250V		10/100	• <b>422.1664</b>
	6h 50/60Hz 380-415V		10/100	• <b>422.1666</b>
3P+N+⊕	3h 50-60Hz 380/440V		10/100	• <b>422.16664</b>
	4h 50/60Hz 100-130V		10/100	• <b>422.1662</b>
	9h 50/60Hz 208-250V		10/100	• <b>422.1665</b>
2P+⊕	6h 50/60Hz 346-415V		10/100	• <b>422.1667</b>
	4h 50/60Hz 100-130V		10/50	• <b>422.3260</b>
	6h 50/60Hz 200-250V		10/50	• <b>422.3263</b>
32A 3P+⊕	9h 50/60Hz 380-415V		10/50	• <b>422.3268</b>
	4h 50/60Hz 100-130V		10/50	• <b>422.3261</b>
	9h 50/60Hz 200-250V		10/50	• <b>422.3264</b>
3P+N+⊕	6h 50/60Hz 380-415V		10/50	• <b>422.3266</b>
	3h 50-60Hz 380/440V		10/50	• <b>422.32664</b>
	4h 50/60Hz 100-130V		10/50	• <b>422.3262</b>
3P+N+⊕	9h 50/60Hz 208-250V		10/50	• <b>422.3265</b>
	6h 50/60Hz 346-415V		10/50	• <b>422.3267</b>



### Straight 62 (\*)

Description		Colour	Pack qty.	Cat. no.
16A 2P+⊕	4h 50/60Hz 100-130V		10/100	<b>422.1660/R</b>
	6h 50/60Hz 200-250V		10/100	<b>422.1663/R</b>
	9h 50/60Hz 380-415V		10/100	<b>422.1668/R</b>

422.

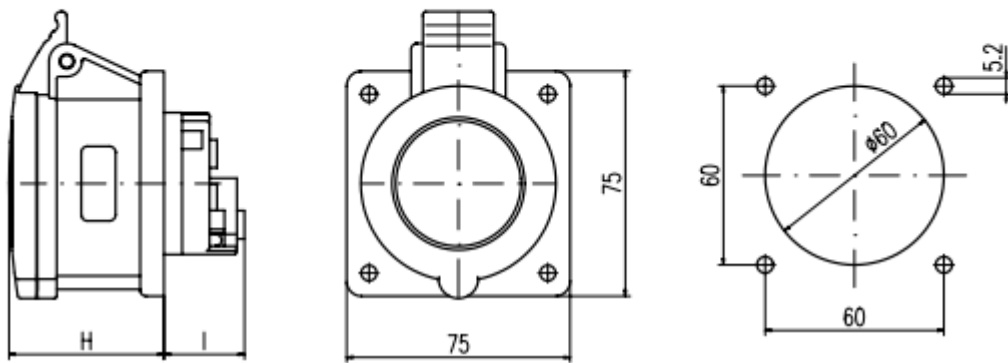

		I	H
16A	2P+ $\frac{1}{2}$	27	51
	3P+ $\frac{1}{2}$	27	51
	3P+N+ $\frac{1}{2}$	27	52
32A	2P+ $\frac{1}{2}$	42	62
	3P+ $\frac{1}{2}$	42	62
	3P+N+ $\frac{1}{2}$	42	63