

Datasheet

RS 1 Gang Metal Clad Switched Outdoor Electrical Socket, Type G - British, 13A, Surface Mount, IP66

RS Stock number: 699-7086



Features

Stylish modern profile

Colour coded terminals with backed out captive screws for easy installation

Covers to seal the fixing screws

2 Earth terminals in socket except WP23 which has 1

1 Earth terminal in mounting box

All cable entries in the 4 sides have removable blanking caps.

Housing will accept accessories from the Nexus range

Cover will stay open to allow for easy access to sockets

See-through cover allows status of switches to be seen

Latched type, 30mA trip current, 40mS trip

Product Images


WP22/MP24

WP21/MP23


Technical Specifications (WP21, WP22 products)

Standard(s)	BS 1363 Part 2
Rating	13 Amp 250V~
Switch type	Double pole
Contact Gap	3mm minimum
Terminal Capacity	3 x 2.5mm ² 3 x 4mm ² 2 x 6.0mm ²
IP rating	IP56 with plug in use
Covered by RoHS directive	No
Covered by WEEE directive	No
WP21	
Size	111mm x 154mm x 80mm
Number of cable entries	5 x 20mm. 1 in each of 3 sides and 2 in the remaining side 1 drill out entry 20/25mm in rear face
WP22	
Size	171mm x 154mm x 80mm
Number of cable entries	8 x 20mm. 1 in each of the 2 sides and 3 in each of the top and bottom faces 1 drill out entry 20/25mm in rear face

Technical Specifications (WP23, WP24 products)

Standard(s)	BS 1363 Part 2
Rating	13 Amp 250V~
Terminal Capacity	3 x 2.5mm ² 3 x 4mm ² 2 x 6.0mm ²
IP rating	IP56 with plug in use
Covered by RoHS directive	No
Covered by WEEE directive	No
WP23	
Size	111mm x 154mm x 80mm
Number of cable entries	5 x 20mm. 1 in each of 3 sides and 2 in the remaining side 1 drill out entry 20/25mm in rear face
WP24	
Size	171mm x 154mm x 80mm
Number of cable entries	8 x 20mm. 1 in each of the 2 sides and 3 in each of the top and bottom faces 1 drill out entry 20/25mm in rear face

WP22/WP24

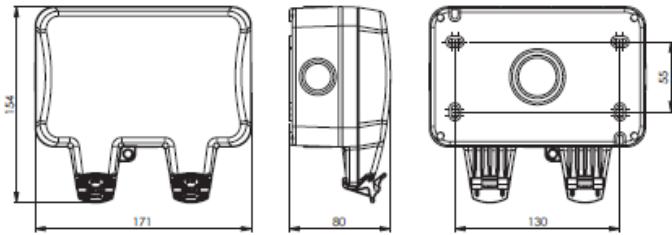

WP21/WP23

