


## D-SUB protective cover - VS-09-SD - 1887086

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

D-SUB protective cover, shell size 1, IP54 degree of protection, for panel mounting frame and sleeve housing VS-09-...



### Key commercial data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 017918 817480
Weight per Piece (excluding packing)	7.08 g
Custom tariff number	85389099
Country of origin	Germany

### Technical data

#### Mechanical characteristics

Locking type	Without
Insertion/withdrawal cycles	≥ 1000
Color	gray

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 80 °C
Degree of protection	IP54

#### Material data

Inflammability class according to UL 94	V0
Housing material	PA
Material	Plastic

# D-SUB protective cover - VS-09-SD - 1887086

## Classifications

eCl@ss

eCl@ss 4.0	27141210
eCl@ss 4.1	27141210
eCl@ss 5.0	27149110
eCl@ss 5.1	27149110
eCl@ss 6.0	27149110
eCl@ss 7.0	27149110
eCl@ss 8.0	27149110

ETIM


ETIM 2.0	EC000241
ETIM 3.0	EC002040
ETIM 4.0	EC002040
ETIM 5.0	EC002040

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

## Drawings

Dimensioned drawing

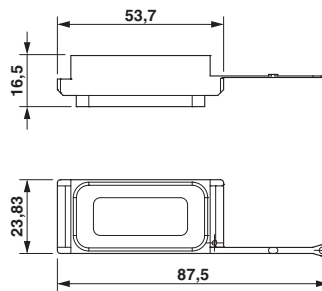

Protective cover for D-SUB