


T12

FILTRASFERA

CON VALVOLA
NON RITORNO



WITH NON RETURN
VALVE

AVEC CLAPET
NON RETOUR

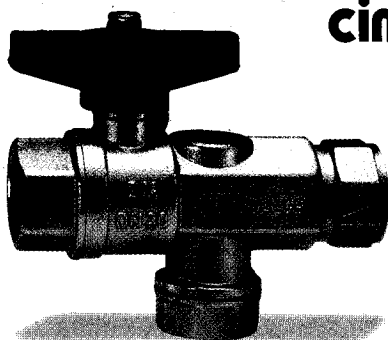


cim 621

DIAGRAMMA PERDITE DI CARICO - FLOW AND PRESSURE DROP
DIAGRAMME DEBITS ET PERTES DE CHARGE

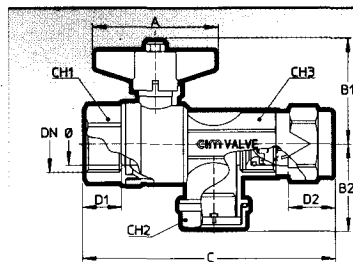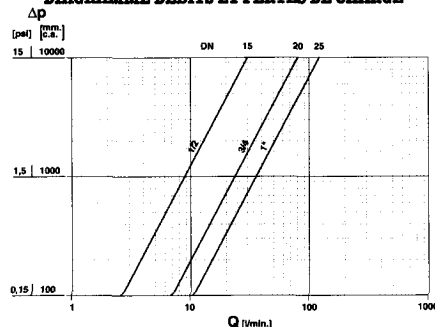

DN	1/2 x 1/2	3/4 x 3/4	1" x 1"
Ø mm.	15	20	25
Grms.	400	585	840
A	50	70	70
B1	52	56	60
B2	39	43	50
C	101	117	141
D1	17	19	21
D2	16	16	16
CH1	25	31	40
CH2	25	30	37
CH3	25	31	38

DIAGRAMMA PERDITE DI CARICO - FLOW AND PRESSURE DROP
DIAGRAMME DEBITS ET PERTES DE CHARGE

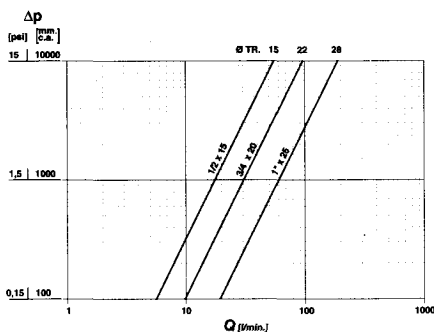


T12

FILTRASFERA

ATTACCHI
A BICONO


WITH COMPRESSION
ENDS

AVEC ECROU BICONE

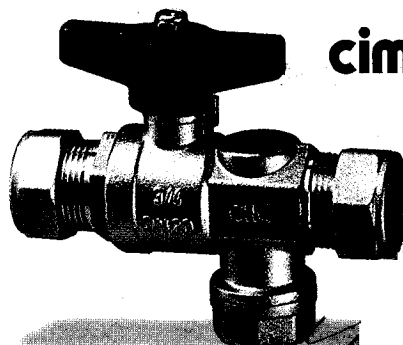

cim 623

DN x T.R.	15 x 15	22 x 22	28 x 28
Ø mm.	15	20	25
Grms.	360	600	860
A	50	70	70
B1	52	56	60
B2	39	43	50
C	97	110	127
CH1	24	32	39
CH2	25	30	37

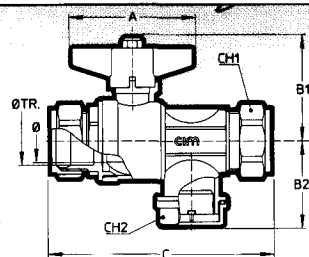


T12

FILTRASFERA

ATTACCHI A BICONO
E VALVOLA NON
RITORNO



WITH COMPRESSION
ENDS AND NON
RETURN VALVE

AVEC ECROU BICONE
ET CLAPET DE NON
RETOUR

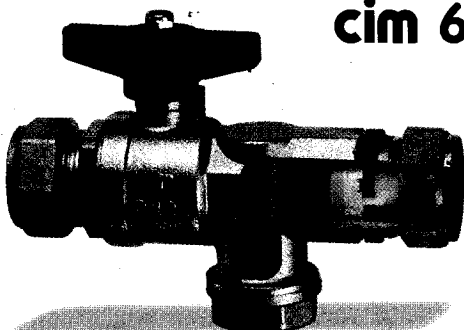

cim 628

DIAGRAMMA PERDITE DI CARICO - FLOW AND PRESSURE DROP
DIAGRAMME DEBITS ET PERTES DE CHARGE

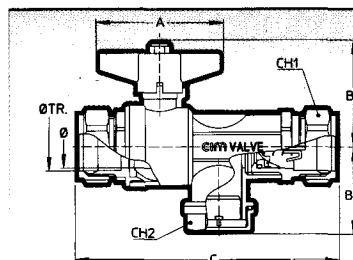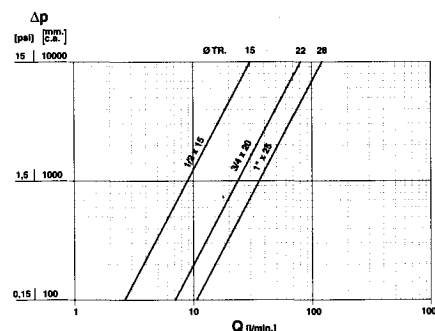

DN x T.R.	15 x 15	22 x 22	28 x 28
Ø mm.	15	20	25
Grms.	405	710	990
A	50	70	70
B1	52	56	60
B2	39	43	50
C	112	132	150
CH1	24	32	39
CH2	25	30	37