



Rotary handle, lockable

Part no.
Article no.

NZM1-XDV
260125

Complete with rotary drive

Delivery programme

Function			Standard, black/grey
Protection class			IP66 UL/CSA Type 4X, Type 12
Locking facility			lockable on the 0 position on the switch using up to 3 padlocks
Project planning information			Complete with rotary drive Can be combined with insulating surround MODAN handle position detection by wire release can be retrofitted
For use with			NZM1(-4), PN1(-4), N(S)1(-4)
Notes			
Circuit-breaker can also be installed in a lying position 90 ° left/right, with the handle still in the same position.			

Approvals


Product Standards
UL File No.
UL CCN
CSA File No.
CSA Class No.
NA Certification


UL489; CSA-C22.2 No. 5-09; IEC60947, CE marking
E140305
DIHS
022086
1437-01
UL listed, CSA certified

Technical data ETIM 4.0

Suitable for switch-disconnector			YES
Suitable for circuit-breakers			YES
With shaft			No
Suitable for emergency switching off			No
Lockable			YES
Color			black

Dimensions

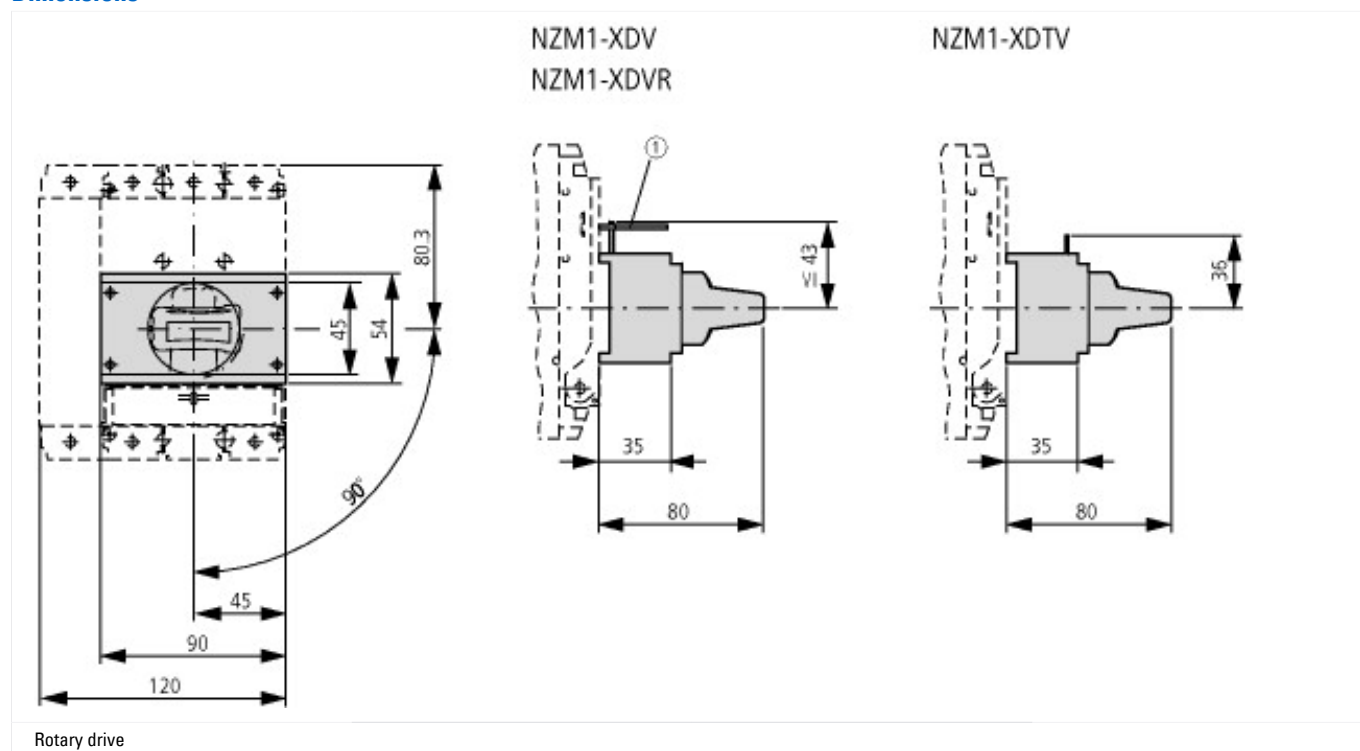

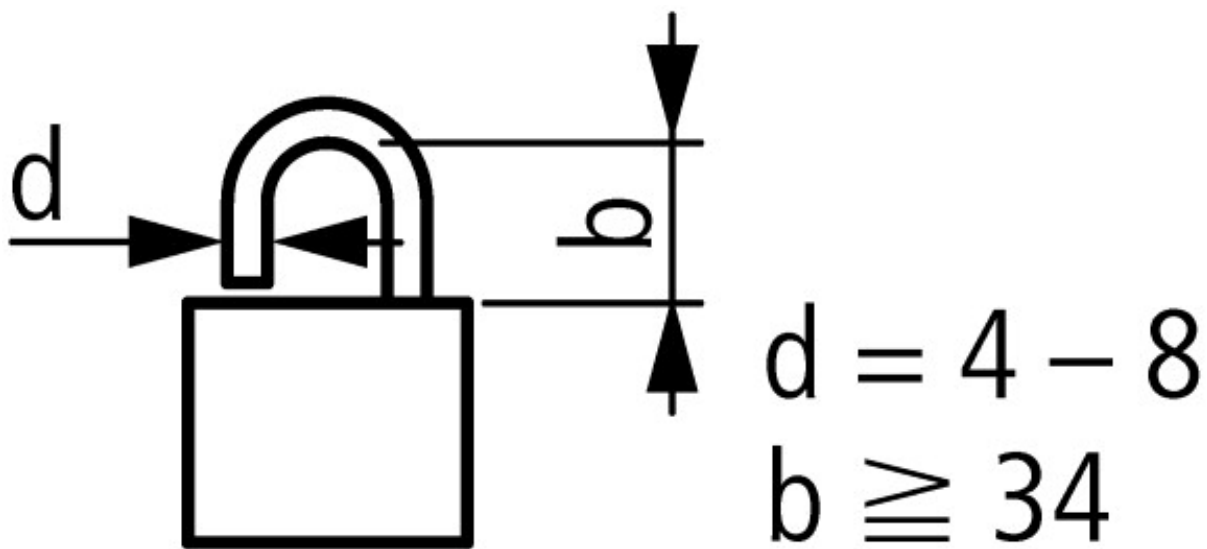

Additional product information (links)

IL01203003Z (AWA1230-1900) Rotary drive

IL01203003Z (AWA1230-1900) Rotary drive

ftp://ftp.moeller.net/DOCUMENTATION/AWA_INSTRUCTIONS/IL01203003Z2010_11.pdf