

B 080805 PC-V0 7024




Bocube
Enclosures, polycarbonate UL 94 V0, single-coloured

Order no.: 96011114

Colour	Graphite grey
Colour of enclosure group	Graphite grey, similar to RAL 7024; light grey, similar to RAL 7035; special colours on request
Protection class	IP 66/IP 67 DIN EN 60529
Enclosure material	ABS or PC UL 94 V0 (material is suitable for outdoor use; f1-listing according to UL 746C), foamed seal; for details please see Technical Information

Scope of delivery: Lid and base, hinged quick-release catches

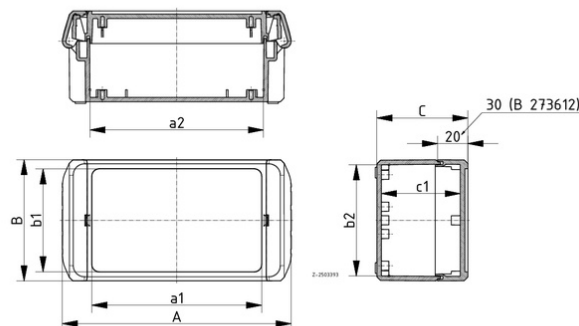

A	89 mm
B	80 mm
C	47 mm
a1	50 mm
a2	52,6 mm
b1	68 mm
b2	73,6 mm
c1	40,5 mm

Technical drawings	3D product data in STEP format: Registration necessary Basic drawing for processing work: 96011114_B-080805-PC-V0-7024-G.dxf (2.8 MB) Catalogue drawing in DXF format: 96011114_B-080805-PC-V0-7024.dxf (3.5 MB) Catalogue drawing in PDF format: 96011114_B-080805-PC-V0-7024.pdf (160 KB)
---------------------------	----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Chapter download	Bocube_GB.pdf (459 KB) Highlights_Bocube.pdf (3.8 MB)
-------------------------	------------------------------------------------------------------------------------------

Accessories



Hinged quick-release catches (Set), polycarbonate UL 94 V0 or ABS

96310103	B SC 08 PC-V0 1023	For B 0808.., B 1008.., B 1408.. Traffic yellow
96310105	B SC 08 PC-V0 7035	For B 0808.., B 1008.., B 1408.. Light grey
96310104	B SC 08 PC-V0 7024	For B 0808.., B 1008.., B 1408.. Graphite grey
96310109	B SC 08 PC-V0 6029	For B 0808.., B 1008.., B 1408.. Mint green
96310102	B SC 08 PC-V0 5002	For B 0808.., B 1008.., B 1408.. Ultramarine blue
96310100	B SC 08 PC-V0 3000	For B 0808.., B 1008.., B 1408.. Flame red



Hand-operated hinged catch (set), polycarbonate UL 94 V0 or ABS

96910103	B SC HB 08 PC-V0	For B 0808.., B 1008.., B 1408.. Traffic yellow
96910105**	B SC HB 08 PC-V0	For B 0808.., B 1008.., B 1408.. Light grey
96910104**	B SC HB 08 PC-V0	For B 0808.., B 1008.., B 1408.. Graphite grey
96910109	B SC HB 08 PC-V0	For B 0808.., B 1008.., B 1408.. Mint green
96910102	B SC HB 08 PC-V0	For B 0808.., B 1008.., B 1408.. Ultramarine blue
96910100	B SC HB 08 PC-V0	For B 0808.., B 1008.., B 1408.. Flame red




Wall brackets

96510004	B WL 7024	For B 08... - B 26... Graphite grey
96510005	B WL 7035	For B 08... - B 26... Light grey




Mounting panels, laminated paper, 2 mm

96601100	B M 0808	For B 0808..
----------	--------------------------	--------------

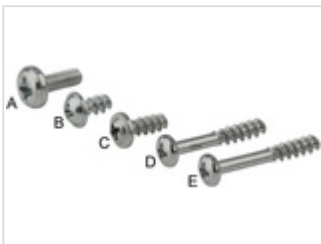

Sets of screws

96600000	B M-SHR 0808	B (for fixing mounting panels B M 0808)
96300000	B SHR	D (for optional screwing of enclosures B 0808 - 2617)

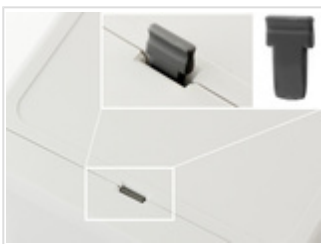

Blanking plugs to determine the hinge side

96410004	B VS 7024	Graphite grey
96410005	B VS 7035	Light grey
96410000	B VS 3000	Flame red

* = Available on request