


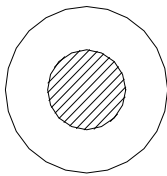

Product Name:	UL1213 28AWG
Product Discription:	UL1213 28AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		Not specified			Conductor		Stranded Sliver plated copper					
Rated Temperature:		105℃, 60 ℃ Oil			Size(AWG)		28					
Reference Standard:		UL758			Construction(±0.008mm)		7/0.127					
Cross Section					Stranded Dia.(mm)Ref.		0.38					
					Insulation Material		PTFE					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.2					
					Insulation Dia.(±0.08mm)		0.89					
Marking					Remark:							
No marking on the cable jacket, have UL label on the Reel.					8739624 Red		8739633 Blue		8739646 Grey		8739655 Violet	
					8739627 Black		8739636 White		8739649 Yellow			
					8739620 Brown		8739630 Green		8739642 Orange			
Applications					Characteristics					Customer Approve		
Internal wiring where not subjected to mechanical abuse, Oil Resistant 60 deg C.					Test Item			Standard Value			Seal & Stamp	
					Test Material			PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m			1000				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)			203(MAX)				
Version	Description	Drawn by	Approved by	Date							Signature:	
0	New document issue	Danniel	Jason	24/04/2015								
											Date:	