


Arteor™ television and telephone sockets

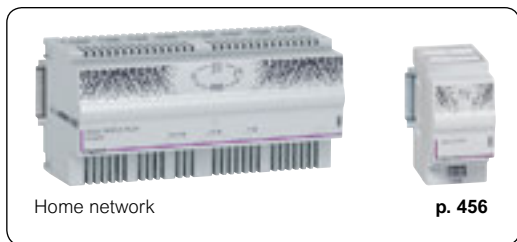

Support frame and plate selection charts **p. 414-421**

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 411) and plates (p. 414 to 421)

Pack	Cat.Nos	RJ 11 and RJ 12 sockets
		Equipped with modular Jack connector with 1/4 turn terminal for fast connection (possible looping)
		RJ 11 - 1 module 4 contacts
10	5 723 00	○ White
10	5 728 00	● Magnesium
		RJ 11 - 2 modules 4 contacts
10	5 723 13	○ White
10	5 728 13	● Magnesium
		RJ 12 - 2 modules 6 contacts
10	5 723 12	○ White
10	5 728 12	● Magnesium
		Telephone sockets With IDC connection Conform to British Telecom
		Single master - 2 modules
10	5 723 10	○ White
10	5 728 10	● Magnesium
		Single secondary - 1 module
5	5 723 01	○ White
5	5 728 01	● Magnesium

Pack	Cat.Nos	Television sockets
		For aerial and satellite installation (with individual demodulator) DTT and HDTV compatible TV: male connector (Ø9.5 mm), attenuation ≤ 1.5 dB R: female connector (Ø9.5 mm), attenuation ≤ 1.5 dB SAT: "F" type connector, attenuation ≤ 2 dB Recommended coaxial cable: 17/19 VATC
		TV sockets single shielded "F" type with screws 0-2400 MHz 1 module
10	5 721 63	○ White
10	5 726 63	● Magnesium
		TV sockets single shielded male Ø9.5 mm 0-2400 MHz 1 module
10	5 721 71	○ White
10	5 726 71	● Magnesium
		TV-R sockets shielded female-male Ø9.5 mm 2 modules
10	5 721 70	○ White
10	5 726 70	● Magnesium
		TV-R-SAT sockets shielded 0-2400 MHz 1 module
10	5 721 72	○ White
10	5 726 72	● Magnesium