 



## Product

### AK 14

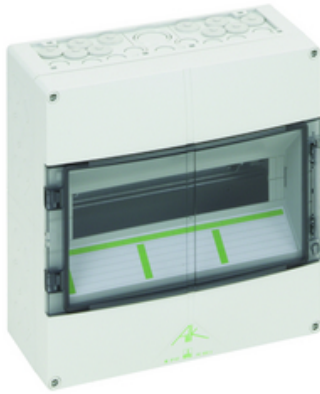

#### Entries

Entries top end:

17 x M20

2 x M20/M25

1 x M32/M40

Entries bottom end:

15 x M20

2 x M20/M25

1 x M32/M40

Entries on each side:

8 x M20

2 x M25/M32

Distribution board, 1 row, 14 modules, screwless PE/N terminal rails each with 3 screwable clamping points, 2.5 - 16 mm<sup>2</sup>, 14 screwless clamping points, 1.5 - 4 mm<sup>2</sup>, elastic entries on top, with cable covering, masking and labelling strips, additional double-membrane seals and other accessories

Article: AK 14

#### Technical Data

##### Dimensions:

Width: 300 mm

Length: 300 mm

Height: 142 mm

##### material:

Base: Polystyrene, grey, similar to RAL 7035

Cover: Polystyrene, grey, similar to RAL 7035

Hinged window: Polycarbonat, transparent

Sealing: Polyurethane

Cover screw: Polyamide 6, fiber-glass reinforced

**Properties:**

Ingress protection:	IP65 - acc. EN 60529 / DIN VDE 0470-1
Number of distribution units:	14
Tackable:	√
Fire protection:	none
Halogen-free:	√
Heavy metals-free:	√
PVC-free:	√
Silicone-free:	√

---

