

Accessories for 200 – 2000A Non-fusible disconnect switches



OZXA-200




OZXA-400



OZXA-800




OEA28

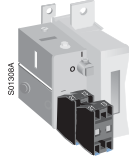


OZXK_



 OTS_L_



OTS_S_

 

OETL-ZX95

Terminal lug kits

For use on:	Wire size	Wire type	Terminal lugs per kit	Kit catalog number	List price
OT200	#4 – 300 kcmil	Cu/Al	6	OZXA-200	
	(6)#14 – #6 AWG	Cu/Al	3	OZXA-206T	
OT400	#2 – 600 kcmil	Cu/Al	6	OZXA-400	
	(2) #2 – 300 kcmil	Cu/Al	6	OZXA-402	
	(6) #14 – #6 AWG	Cu/Al	3	OZXA-406	
	(2) #4 – 500 kcmil	Cu/Al	6	OZXA-33	
OT600	(2) #2 – 600 kcmil	Cu/Al	6	OZXA-800	
OT800, OT1200	(4) #2 – 600 kcmil	Cu/Al	6	OZXA-1200	
OETL-NF1600	(4) #1/0 – 750 kcmil	Cu/Al	6	DSK8TL	
OETL-NF2000	(6) #1/0 – 750 kcmil	Cu/Al	6	DSK8TM	

Auxiliary contacts

Description	For use on:	AC thermal amp rating	AC rated voltage	Catalog number ^①	List price
1 N.O. 1 N.C. Module for aux. contacts	OT200-1200	10	600	OA1G10	
		10	600	OA3G01	
		10	600	OEA28	
1 N.O. + 1 N.C. 2 N.O. + 2 N.C. 4 N.O. + 4 N.C.	OETL-NF1600 & OETL-NF2000	10	600	OZXK-1	
		10	600	OZXK-2	
		10	600	OZXK-3	

① Mounting on the side of the switch: max. 8 auxiliary contact blocks with the OEA28 module

Mounting under the mechanism cover: OT200: Max. 4 test contacts or 2 test contacts + 2 test indication contacts.

OT400-600: Max. 4 test contacts + 4 test indication contacts. OT800-1200: Max 4 test indication contacts + 8 test contacts. The test contacts can be used as standard auxiliary contacts as well.

Detachable neutral links

Description	For use on:	AC thermal amp rating	AC rated voltage	Catalog number	List price
Mounting separately on baseplate protected construction	OT200	200	600	OXN250	
	OT400	400	600	OXN400	
	OT600	600	600	OXN800T	

Terminal shrouds (Snap-on mounting, grey plastic, IP30) ① For both line and load sides

Description	For use on:	Qty per pkg	Quantity for full protection (pcs.) ^②	Catalog number	List price
Long type	OT200	3 x 1P	2	OTS250G1L/3	
Short type	OT200	3 x 1P	2	OTS250G1S/3	
Long type	OT400	3 x 1P	2	OTS400G1L/3	
Short type	OT400	3 x 1P	2	OTS400G1S/3	
Long type	OT600	3 x 1P	2	OTS800G1L/3	
Short type	OT600	3 x 1P	2	OTS800G1S/3	
Long type	OT800 -1200	3 x 1P	2	OTS1600G1L/3	
Short type	OT800 -1200	3 x 1P	2	OTS1600G1S/3	

Shaft extension coupler

Description	For use on:	Catalog number	List price
Joins two shafts together for applications where extended length is required	6mm shafts 12mm shafts	OESA-ZX167 OETL-ZX95	

Mounting feet

Description	For use on:	Catalog number	List price
Mounting feet Screw	OT200	OEZKL1 FPMH3.5X12X-TX15	
Mounting feet Screw	OS200/400, OT400/600	OEZKL2 FPMH5X14X-TORX	