



Deep groove ball bearings, single row

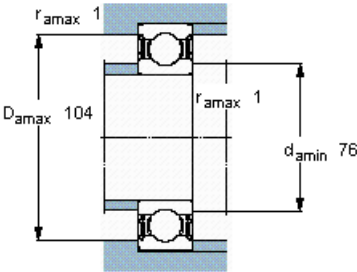

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
70	110	20	39,7	31	1,32	-	3600	0,60	6014-2RS1 *

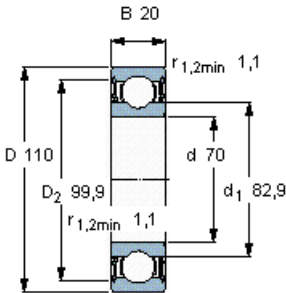

Calculation factors

k_f 0,025
 f_0 16