



# Feed through and ground terminal blocks

## Spring clamp, U DIN 3


### D 2,5/5...L - 2.5 mm<sup>2</sup> blocks - 5 mm .198" spacing

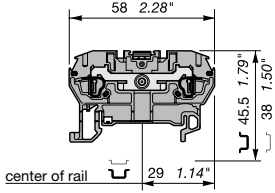


D 2,5/5.2L

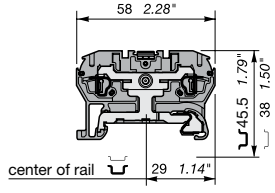


D 2,5/5.P.2L

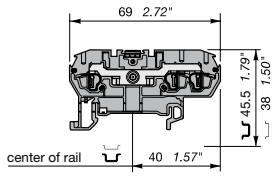


D 2,5/5.3L

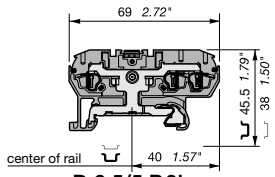


D 2,5/5.P.3L

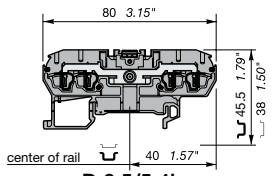

D 2,5/5.4L

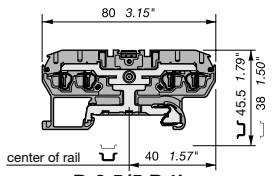

D 2,5/5.P.4L

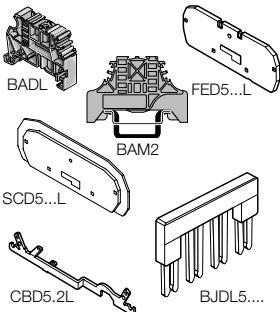

#### Characteristics

		IEC		UL	CSA
		NFC	DIN		
Wire size mm <sup>2</sup> / AWG	Solid	0.12 - 4 mm <sup>2</sup>		26-12 AWG	26-12 AWG
	Stranded	0.12 - 2.5 mm <sup>2</sup>			
	Isolated ferrules	0.5 - 2.5 mm <sup>2</sup>			
Voltage	V	600		600	600
Current	A	24		15	15
Short circuit current (D 2,5/5.Pl...L)	A / s	300 A/1s			
Short circuit current (D 2,5/5.P...L)	A / s	300 A/1s			
Rated wire size	mm <sup>2</sup> / AWG	2.5 mm <sup>2</sup>		12 AWG	12 AWG
Wire stripping length	mm / inches			9.5 mm / .37"	

#### D 2,5/5.2L Selection

Description	Type	Packaging	Catalog number
Standard block grey	D 2,5/5.2L	50	029002127
Standard block blue	D 2,5/5.N.2L	50	029002321
Standard block yellow	D 2,5/5.2L	50	029002725
Standard block orange	D 2,5/5.2L	50	029002220
Standard block red	D 2,5/5.2L	50	029002422
Standard block black	D 2,5/5.2L	50	029002624
Standard block green	D 2,5/5.2L	50	029002806
Standard block white	D 2,5/5.2L	50	029002523
Standard block brown	D 2,5/5.2L	50	029046400
Standard block violet	D 2,5/5.2L	50	029046501
Ground block green/yellow	D 2,5/5.P.2L ①	50	029002907

#### D 2,5/5.3L Selection

Standard block grey	D 2,5/5.3L	50	029003121
Standard block blue	D 2,5/5.N.3L	50	029003323
Standard block orange	D 2,5/5.3L	50	029003222
Standard block red	D 2,5/5.3L	50	029003424
Standard block black	D 2,5/5.3L	50	029003626
Standard block brown	D 2,5/5.3L	50	1SNS43000Z1081
Standard block white	D 2,5/5.3L	50	029003525
Standard block yellow	D 2,5/5.3L	50	029003727
Ground block green/yellow	D 2,5/5.P.3L ①	50	029003901

#### D 2,5/5.4L Selection

Standard block grey	D 2,5/5.4L	50	029001125
Standard block blue	D 2,5/5.N.4L	50	029001327
Standard block orange	D 2,5/5.4L	50	029001226
Ground block green/yellow	D 2,5/5.P.4L ①	50	029001905

#### Accessories

Description	Type	Packaging	Catalog number
End stop (light grey)	(screwless) BADL 9 mm	50	039990302
	(with screw) BAM2 9.9 mm	50	039996701
End section	grey FED5.2L 2.5 mm ②	20	029106124
	orange FED5.2L 2.5 mm ②	20	029106225
	grey FED5.3L 2.5 mm ③	20	029105122
	orange FED5.3L 2.5 mm ③	20	029105223
	grey FED5.4L 2.5 mm ④	20	029104120
	orange FED5.4L 2.5 mm ④	20	029104221
Separator	orange SCD5.2L 2.5 mm ②	20	029135204
	grey SCD5.2L 2.5 mm ③	20	029135103
	orange SCD5.3L 2.5 mm ③	20	029136206
	orange SCD5.4L 2.5 mm ④	20	029137200
	Jumper bar, IP20	2 poles BJDL5.2 24 A	50
	3 poles BJDL5.3 24 A	50	029110324
	4 poles BJDL5.4 24 A	50	029110425
	5 poles BJDL5.5 24 A	20	029110526
	10 poles BJDL5.10 24 A	20	029111026
Shield connector	CBD5.2L 0.5 mm ④	50	029107724

① With rail contact.  
 ② Only for D 2,5/5...2L  
 ③ Only for D 2,5/5...3L  
 ④ Only for D 2,5/5...4L