


Deep groove ball bearings, single row, seal on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
25	37	7	4,36	2,6	0,125	-	11000	0,022	61805-2RS1

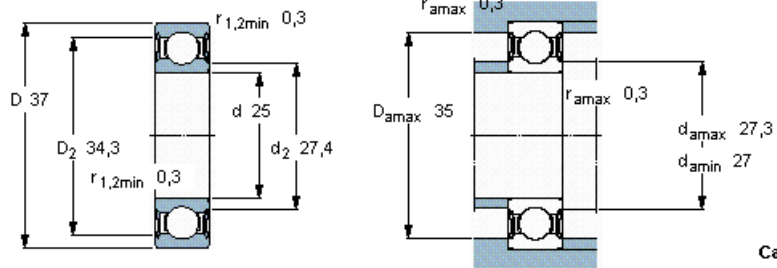

Calculation factors

$k_r = 0,015$
 $f_0 = 14$