

This is a sample photo.

**ORDER SYMBOL:** PC 282813T



**EL.number** **EAN:** 6418074005519

Sweden:  
Denmark:  
Finland: 3423813

**INCLUDING:**  
Enclosure body, cover, 4 slotted cover screws, and mounting screws.

**APPROVALS:**  
USA: UL Type 1, 3, 3S, 4, 4X, 12 (E75645 Vol.1 Sec.2); UL 94-V0  
EURO: IP 67; UL 94-V0  
OTHERS: IEC 529, CE, EEI, SETI 154171-01, CSA LR 49336-7

FIBOX SOLID PC

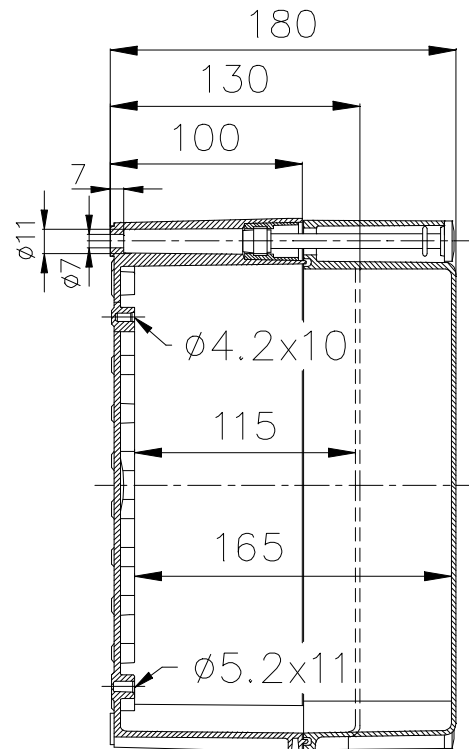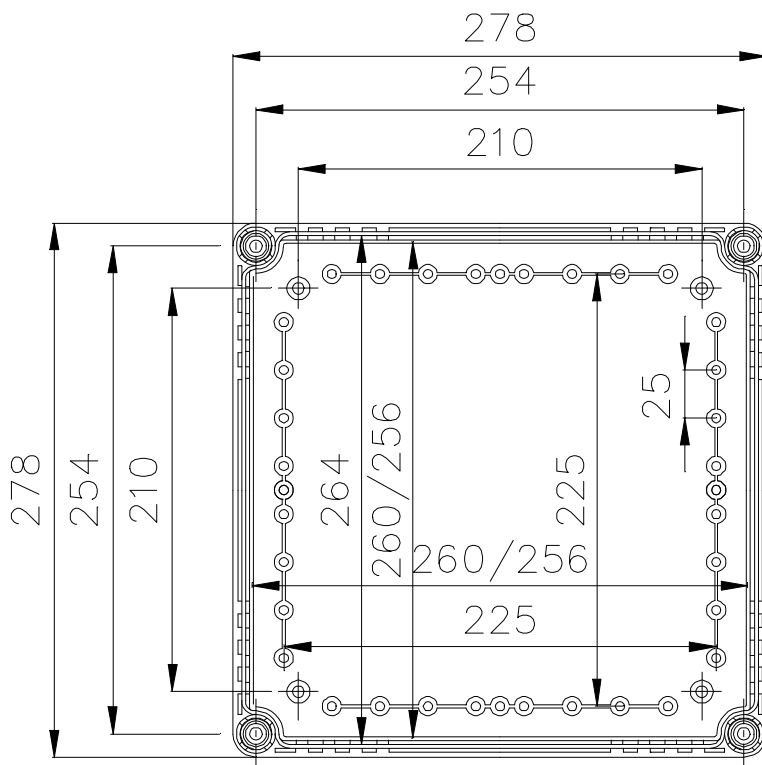

**TECHNICAL INFORMATION:**

Standard colour: RAL 7035  
Ingress protection: IP 67 (IEC 529)  
Flame resistance: UL 94-V2

Temp.range in cont. use: Max. +80 °C  
Temp. range of material: - 40 °C - + 120 °C

**ACCESSORIES**

Extension frame	EKJZR	DIN-Rail	EKV 24
Extension frame	EKMZR	DIN-Rail	EKV 32
Extension frame	EKOZR	DIN-Rail	EKV 34
Extension frame	EKPZR	Corner plug	MB 10523
Extension frame	EKTZR	Fastening lug	MB 10674
Extension frame	EKUZR	Earth bar support	MB 26069
DIN-Rail	EKV 12	Earth bar set	MR 26059
DIN-Rail	EKV 14		
DIN-Rail	EKV 22		