
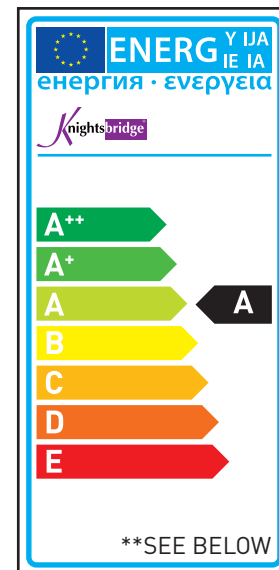


# DATA SHEET: FLB SERIES

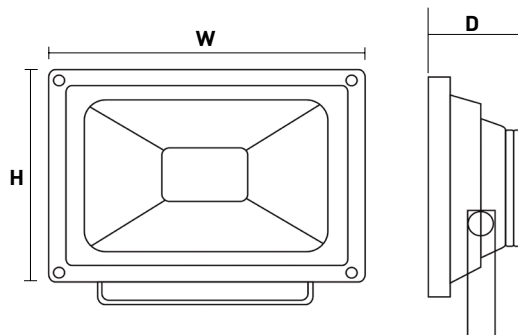

## COMMON TO ALL SIZES

Recommended product location	Outdoor
Lamp Supplied	Integral LED
Voltage (V)	230V 50Hz
Running current (I)	Dependant on lamp wattage
CCT	4000K
Dimmable	No
Class	Class I, Must be earthed
IP	IP65
Photometric testing	Yes
Instruction sheet	Yes
Origin of manufacture	China
• Body	Aluminium
• Diffuser	Glass
• Screws	Stainless steel cross head
Method of fix	Direct fixing – screws provided
Electrical connections	300mm Flex cable
Running gear / make	Integral
CE mark	Yes
Quality assurance system	Yes ISO 9001 QMS
Batch coding details on product	Yes
Certificate of conformity (Held on File)	Yes
Warranty	3 Years
Manufactured in accordance to:	BS EN 60598

	FLB15	FLB25	FLB50
Product Weight	0.95kg	1.05kg	2.25kg
Lamp Wattage (W)	14.3W	25.5W	48.3W
Lumen Output	1150lm	2000lm	4000lm
Lm/W	80lm/W	79lm/W	83lm/W
**Energy per 1000h	14.3W	25.5W	48W
Dimensions:			
• Height	185mm	232mm	328mm
• Width	225mm	285mm	285mm
• Depth	50mm	55mm	65mm



ML Accessories Ltd. reserves the right to withdraw, improve or modify any design without prior notification.  
ML Accessories Ltd. cannot be held responsible for the incorrect application of any product.  
ISSUE SB-02-15-V001