

GLS Rough Service

A55 ROUGH SERV 60W 240V FR E27

0029385



Range features

- Extra durable lamp resistant to vibrations
- Ideal for use in industrial and working environments like garages etc
- Available in pearl finish outer bulb
- Extended 1500 hour service life
- Not suitable for household room illumination
- Intended for use in rough service applications



PRODUCT OVERVIEW

Light colour	825 Homelight
Ordering number	0029385
Technology	Incandescent
Average life (Rated) (h)	1000
Energy class	E
Lamp shape	GLS A55
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	E27
Type	Rough Service
EAN code	5410288293851
CRI (Ra)	100
Colour temperature (K)	2500
Luminous flux (Rated) (lm)	550
Watt (Nominal) (W)	60
Voltage (V)	240

GLS Rough Service

A55 ROUGH SERV 60W 240V FR E27

0029385

DATA TABLE

General data

Ordering number	0029385
Technology	Incandescent
Average life (Nominal) (h)	1000
Average life (Rated) (h)	1000
Energy saving lamp	No
Energy class	E
Lamp shape	GLS A55
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	E27
Type	Rough Service
EAN code	5410288293851
E-number SE	8355049
E-number FI	4743707
Long description	Extra durable lamp resistant to vibrations. Ideal for use in industrial and working environments like garages etc. Available in pearl finish outer bulb. Extended 1500 hour service life. Not suitable for household room illumination. Intended for use in rough service applications
Product name	A55 ROUGH SERV 60W 240V FR E27
Lamp mercury content (mg)	0
Starting time (max) (s)	0.01
Warm-up time to 60% of full light (max) (s)	Instant full light
Control gear required	No
Fixture rating	Open
IEC Reference	IEC 60064
IEC Reference 2	IEC 60432-1
Intended purpose	Rough Service
No. of switching cycles before premature failure (min)	NA
Special purpose lamp	Yes
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

GLS Rough Service

A55 ROUGH SERV 60W 240V FR E27

0029385

Optical data

Light colour	825 Homelight
CRI (Ra)	100
Suitable for accent lighting	No
Colour temperature (K)	2500
Luminous flux (Rated) (lm)	550
Lumen maintenance at end of nominal life (%)	NA
Luminous flux (Nominal) (lm)	550

Electrical data

kWh per 1000 hours burning time	60
Watt (Rated) (W)	60
Watt (Nominal) (W)	60
Voltage (V)	240
Lamp power factor	1

Physical data


Weight (kg)	0.03
Lamp Length (mm) - C/L	95
Max. Lamp Diameter (mm) - D	55.8
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	10.60 x 5.90 x 5.90
Outer package dimensions (L x W x H) (cm)	55.00 x 32.00 x 26.00

GLS Rough Service

A55 ROUGH SERV 60W 240V FR E27

0029385

TECHNICAL DRAWINGS

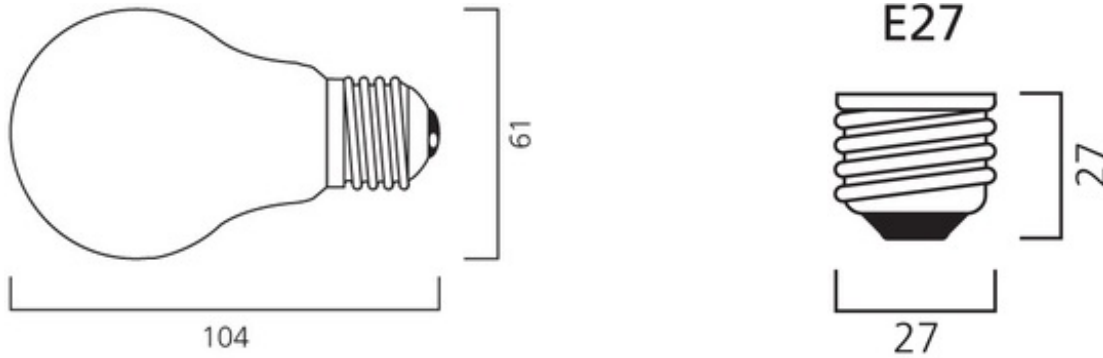

ENERGY LABEL

