

6972H Adaptor, bit holder

DIN 7427 Form A.


Drive: 1/4" DIN 3121-G 6,3 ISO 1174.

Finish: Nickel and chrome-plated.

Material: VANADIUM-EXTRA.

For screwdriver bits with 1/4" male hexagon drive:
DIN 3126-C 6.3 ISO 1173.

* with spring collar.

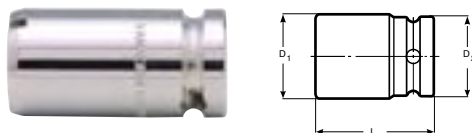

Product code	EAN 731415+				L mm	D2 mm		
6972H	1215934	1	1/4**	1/4"	26.0	13.0	K560F-1	18

7407H-7409H Adaptors, bit holders

Finish:

Model 1: Phosphated.

Model 2: Phosphated.

Material: VANADIUM-EXTRA.

Bit-holding device: For screwdriver bits with 1/4", 5/16", 11 mm male hexagon drive: DIN 3126-C, ISO 1173.

Model 1: DIN 7427-A.

Model 2: Do not conform to DIN 3126-C, ISO 1173.

* with spring collar.

** with locking screw.



Product code	EAN 731415+				L mm	D2 mm		
7407H	1218249	1	* 1/4"	3/8"	26	19	K560F-2	35
7408H	1218300	1	* 5/16"	3/8"	26	19	K560F-2	43
7409H	1218355	1	** 11 mm	3/8"	34	22	K560F-3	43

7807H-7809H Adaptors, holder

Finish:

Model 1: Phosphated.

Model 2: Phosphated.

Material: VANADIUM-EXTRA.

Bit-holding device: For screwdriver bits with 1/4", 5/16", 11 mm male hexagon drive: DIN 3126-C, ISO 1173.

Model 1: DIN 7427-A.

Model 2: Do not conform to DIN 3126-C, ISO 1173.

* with spring collar.

** with locking screw.



Mo. 1



Mo. 2

Product code	EAN 731415+		Mo.			L mm	D2 mm		
7807H	1232764	1	* 1	1/4"	1/2"	38	25	K560F-4	70
7808H	1232771	1	* 1	5/16"	1/2"	38	25	K560F-4	75
7809H	1232788	1	** 2	11.2 mm	1/2"	38	25	K560F-4	90

