


Item no.: 770-134  
 Product description: plug with relief housing 4 pole pin spacing 10 mm / 0.394 in  
 100% protected against mismatching wire diameter 9-13 mm

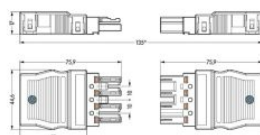

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Product group	20 (WINSTA)
pole count	4
Cross section [mm <sup>2</sup> ]	0.5 - 4 mm <sup>2</sup>
Cross section [AWG]	20 - 12 AWG
Connection method	CAGE CLAMP®S Connection
Number of strands	2
Measured voltage EN	400 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	25 A
Weight	26.435 g
Color	white
No. of connection Points	8
No. of potentials	4
Height	17 mm
Height	0.669 in
Width	44.6 mm
Width	1.756 in
Depth	75.9 mm

Depth	2.988 in
Strip length from	9 mm
Strip length to	9 mm
Strip length	0.35 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
770-134	ABS	06-HG154986/11-PDA	400	25	0,5-4,0
770-134	CBCertificateVDE	DE1-29543	250/400	25	0,5-4
770-134	CCA		400	25	0,5-4,0
770-134	cURus	E45171	600	20	12
770-134	DNV	E-9217	400	25	4
770-134	GL	42875-02HH	400	25	4
770-134	KEMA		400	25	0,5-4,0
770-134	LR	02/20050(E3)	250	25	2,5
770-134	PRS	TE/1719/880590/08	400	25	0,5-4,0
770-134	PSE	JET0695-43009-1002	600	20	12
770-134	VDE	Ausweis.Nr.30726	250/400	16/25	0,5-4,0

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected