


# KL-120




Large 16-digit, 2-line LCD

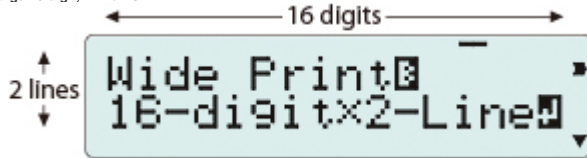

The large LCD displays up to two 16-digit lines, so you can easily confirm the spelling of words you input.  
Handles 18, 12, 9 and 6mm tape widths.

Wide, high-definition print head with max. 12mm print height/200 dpi resolution

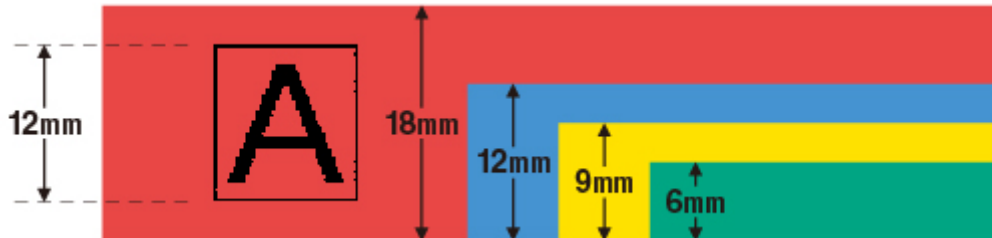

Prints up to 2 lines (18 or 12mm tape).

A 2-line printing capability adds further label-making convenience.



Print preview

Using the print preview to check the print image before printing is a convenient way to reduce printing errors.



- Built-in font: Sans-serif · 3 character effects (Shading/Underline/Box)
- 3 character styles (Normal/Bold/Outline) · Tape length setting · Character pitch · Letter align
- Printing number setting · Layout according to use · Handles 14 national languages
- 5-language message switching (English/Spanish/French/German/Italian)
- QWERTY keyboard · Power supply: 6 x AA-size alkaline (LR6) batteries (sold separately)

**KL-120**

Model	KL-120	
Keyboard layout	QWERTY	
Display	LCD	96 x 16 dots
	Display (input data)	16 digits x 2 lines
Usable tape widths (mm)	24	No
	18	Yes
	12	Yes
	9	Yes
	6	Yes
Printing resolution	200 dpi/96 dots	
Unit of length switching	cm/inches	
Printing speed (mm/sec.)	6.0	
Maximum printing height (mm)	12	
Maximum printing lines	2	
Fonts	Sans-serif	Yes
	Sans-serif italic	No
	Sans-serif rounded	No
	Roman	No
	Roman italic	No
Character styles	Normal/Bold/Outline	
Character effects	Shading/Underline/Box	
Built-in character types	248	
Alphanumeric characters	62	
Special characters/symbols	87	
Illustrations	N/S	
Countries' characters	99	
Frame printing	N/S	
Print preview	N/S	
Tape length setting	N/S	
Layouts according to use	18	
Mirror printing	Yes	

Printing direction	Horizontal
Printing number setting	9
Design logos	N/S
Numbering	N/S
Barcode printing	N/S
Languages supported	14*1
Message switching	5 languages*2
Print job memories	80 characters x 2
Copy and paste	N/S
Auto power off	Yes
Maximum characters per input data	80
Power supply	6 x AA-size alkaline (LR6) batteries (sold separately)
Approximate battery life*3	4 tape cartridges
Dimensions*4: H x W x D (mm)	54.5 x 189 x 115
Approximate weight (g)*5	430
Bundled tape cartridge	12mm x 1

- \*1. English/Spanish/French/Portuguese/Czech/Polish/Hungarian/German/Italian/Dutch/Finnish/Swedish/Danish/Norwegian
- \*2. English/Spanish/French/German/Italian
- \*3. Continuous printing
- \*4. The height dimension includes the feet.
- \*5. Not including batteries