


**NRGF...**

Network Type : Industry

Preinsulated Fork Terminals

Description :

- Tin-plated copper.
- Barrel with funnel entry.
- Grooves in the barrel for a better electrical contact and a better tensile strength. "N" single crimp series:
- Polyamide insulation sleeve.
- Max. operating temperature: +105°C.
- "Easy entry" conical entry.
- Flammability rating: UL94V2.

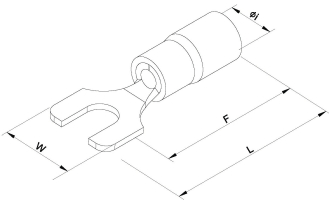

Color	Conductor size (mm <sup>2</sup> )	Item code	Ref.	Packaging	Cable insulation max Ø	Stud size (Ø mm)	W	Ø i	F	L
■	2.5	7212104	C100NRGFB1-4	100	4,4	4	8	2.5	16.5	20.5

