

## HeatSeal™ H310

### The A3 'Standard'


With it's 318 mm 'throat' and it's Photo Quality capability, the H310 opens up new possibilities: maps, charts, menus, posters, notices, technical drawings, etc.

- Lamination width\* from ID size to **A3 Max** (318 mm)
- Pouch capability – 2 x 75 (150 Total), 2 x 100 (200 Total) & 2 x 125 (**250 Total**) Micron
- Carrier-free performance
- **2 x 'Heated Roller' Technology**
- Variable Temperature + 'Cold' setting
- Up to 65 A4's per hour capacity or 90 with GBC High Speed Pouches

\* Lamination Width is the maximum insert width

### Features & Benefits

- 1 Variable temperature:**  
For photo quality
- 2 Exit Tray**  
Keeps the laminated product straight on exit minimising curling and warping
- 3 Release lever:**  
Anti-jam function to solve any miss-feeding problems
- 4 'Ready Glow' Throat**  
Using the 'Traffic Light' principle, it glows green when correct operational temperature is reached and red when the temperature is still adjusting to the setting.
- 5 Auto switch off after 1 hour**
- 6 Only 5 minutes 'Warm up' period**
- 7 Use High Speed Pouches to increase speed with 30%.**

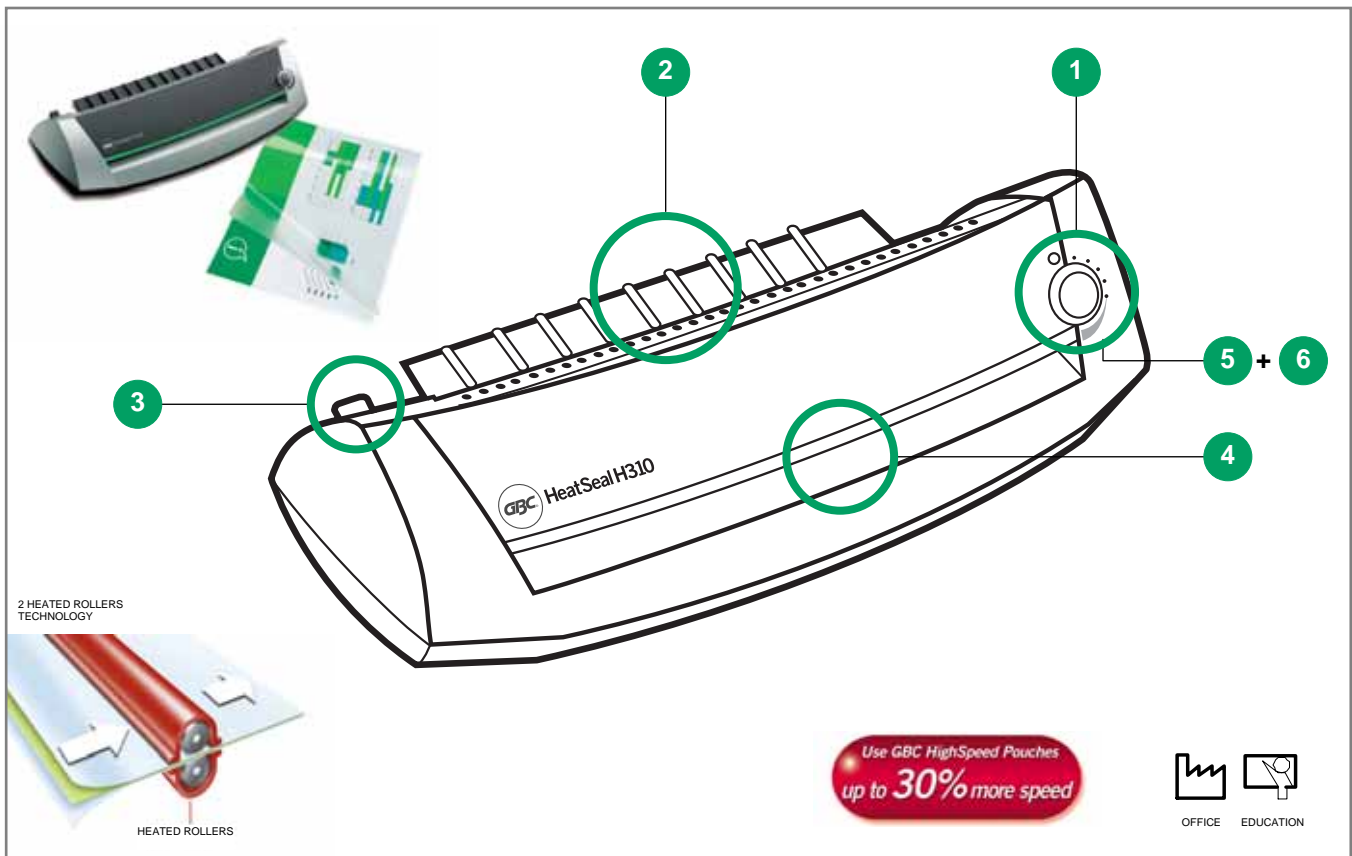

### Technical Specifications

Photo quality	Yes	Pouch counter	-
Heat-up Time (75 mic)	5 min.	Auto switch off	Yes, after 1 hour
Speed mm/min.	330	Time to laminate	55 sec.
Temperature control	Variable	1 Standard A4 Pouch	
Cold Lamination	Yes	A4 Laminates / hr*	65
Speed control	Fixed	Time to laminate	39 sec.
Rollers	2	1 High Speed Pouch	
Max. Document size	A3	High Speed Pouches	Yes
Max. pouch thickness	2x125 Micron (250 Total)	Laminates / hr*	92
Ready Lamp	-	Warranty	2 years
Ready Glow	Yes	Dimensions	476x173x117
Release Function	Yes	Certification	GS / TÜV / CE
Reverse	-	Weight	3.75 kg
Display	-	Power Consumption	500W/2.2A
		Watts / Amps	

\* Estimates only

### Product Codes:

EU 1702590  
UK 1702600



www.gbceurope.com