




TLS 2200®/TLS PC Link™ Labels

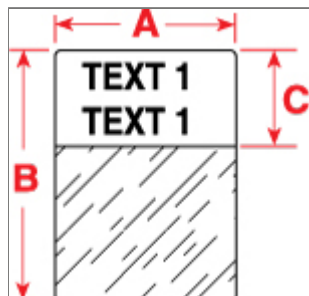

Labels for the TLS 2200® & TLS PC Link™ Thermal Transfer Portable Printers. Please Note: This material is UL recognised with its respective ribbon. See the "Recommended Ribbon Series" for the appropriate ribbon to use.

Specifications

Article Number: 018584
Order Reference: PTL-31-427-RD
Size - Width (mm): 25.4
Size - Height (mm): 38.1
Finish: Matt
Colour: Red/Transparent
Printable Area - Width (mm): 25.4
Printable Area - Height (mm): 12.7
Material Type: Self-Laminating Vinyl
Brady Material Number: B-427
Adhesive: Acrylic
Approval/Compliance: UL Recognised
Max. Service Temp. °C: 70
Special Properties: Excellent abrasion and smudge resistance, Excellent water & oil resistance, Self-Extinguishing, Self-Laminating
QTY. per Row: 1
Max. Lines of Text: 5
Max. Characters per Line: 24
Printer Compatibility: TLS2200, TLSPCLink
Voice/Data Application: Communications Cables
Wire Gauge: 10 to 4
Industry: Data Communications, Electrical
Application(s): Communications Cables, Panel Identification, Voice/Data Identification, Wire & Cable Marking

For further information on this product or for details of a local Brady Authorised Distributor, please use the "Contact Us" button