



Datasheet

Stock No: 748-2119

ENGLISH

RS Pro Brown Equipment Wire, 0.5 mm² CSA, 1000 V 3 A 20 AWG, 100m




BS 4808

Cable Construction

Conductor	Tinned Copper
square(mm ²)	0.5
Construction	T0.2±0.008×16
Standard Dia.(mm)	0.92
Insulation	PVC
Thickness	0.3
Insulation Dia.(±0.1mm)	1.60

Design

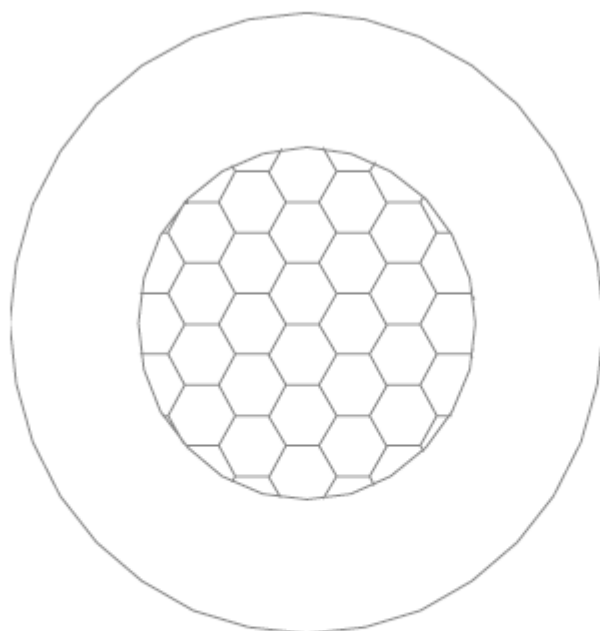

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<37.7
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1000

Manufactured to BS4800 (Technical Paints British Standards)

Flammability Test: IEC EN60332-1