

Mounting brackets

Festebraletter

TYPE FBS 205825


Dim./Mål: 135x20x10mm

2 mounting brackets per unit. Designed for type:

2 festebraletter pr. enhet.

Beregnet for type:

**719, 8421, 9522,
9150, 9521, 9221,
9527, 2026, 9623,
2024, 9726, 2023,
2047**

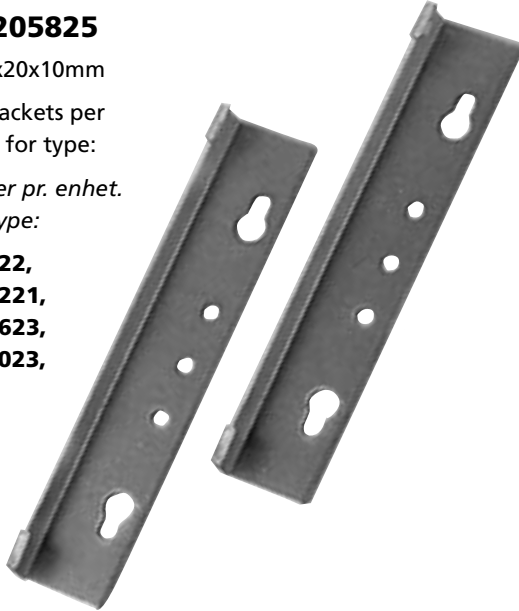

TYPE FAS 207724


Dim./Mål: 80x20x8mm

2 mounting brackets per unit. Designed for type:

2 festebraletter

pr. enhet. Beregnet for type:

**9120, 9320,
9322**

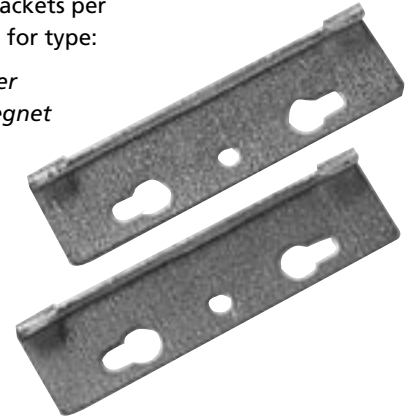

TYPE LME 207818


Dim./Mål: 93x75mm

1 mounting bracket per unit. Designed for type:

1 festebralett pr. enhet.

Beregnet for type:

**6820, 8930, 8931,
6823, 8937, 7504**

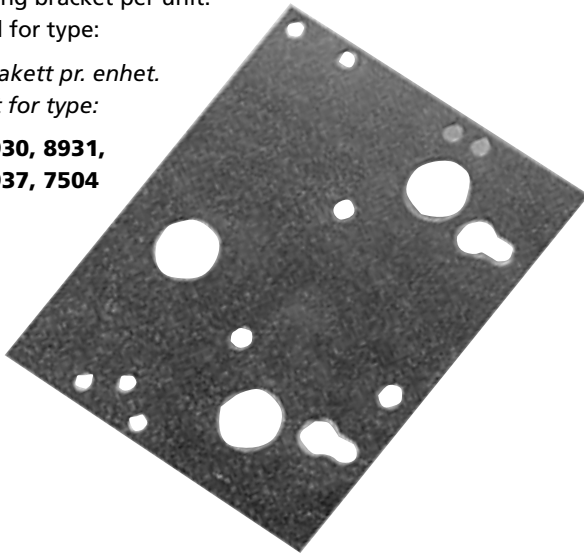

TYPE FCS 207773

Dim./Mål: 135x20x20mm

2 mounting brackets per unit. Designed for type:

2 festebraletter pr. enhet.

Beregnet for type:

**8921, 9260, 2043, 2044,
9660, 2025**



24112005


TYPE 202906

Dim./Mål: 46x47x36mm

1 mounting bracket per unit. Designed for type:

1 festebrakett per enhet. Beregnet for type:

2240, 2121, 2122, 2124, 2125, 2115


TYPE 201565

Dim./Mål: 60x69x38mm

1 mounting bracket per unit. Designed for type:

1 festebrakett per enhet. Beregnet for type:

9920, 9921, 9922, 9940 2246, 2215, 2515


TYPE 201970

Dim./Mål: 72x82x45mm

1 mounting bracket per unit. Designed for type:

1 festebrakett per enhet. Beregnet for type:

2020, 2022, 2040, 2415


TYPE 9000-16 KLIPS ENGAGEMENT FOOT

FM4 engagement foot for TS-35 (35 mm DIN rail). Used in combination with mounting brackets. Supplied in two-pack.

FM4 klips for TS-35 (35 mm DIN skinne). Brukes i kombinasjon med festebraketter. Pakket i poser à 2 stk.

24112005