


Tapered roller bearings, single row



Principal dimensions			Basic load ratings		Fatigue load limit	Speed ratings		Mass	Designation
d	D	T	dynamic	static	P_u	Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
35	80	22,75	72,1	73,5	8,3	6700	9000	0,52	30307 J2/Q

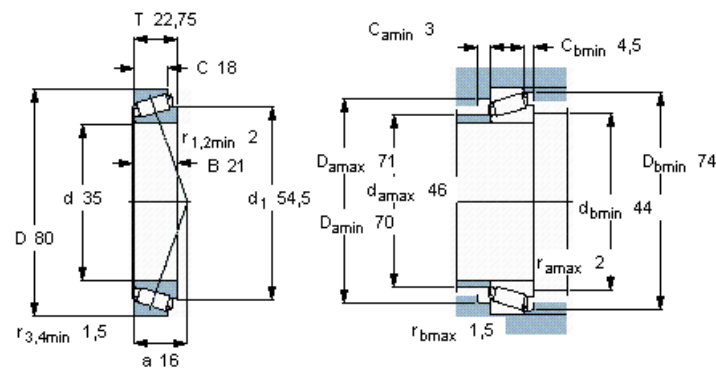

Calculation factors

e 0,31
 Y 1,9
 Y_0 1,1