




PRODUCT DATASHEET

Strada-A series

last update 15/2/2013

Luminaire: Ledil Oy C10818_Strada-A-XP C10818_Strada-A-XP
Lamps: 1 x Cree XP-E (white)

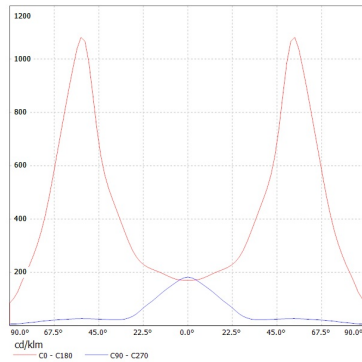

Ordering number C10818 Description 1

Family	Strada-A	FWHM	68+136 degrees
Type	Lens	Efficiency	93 %
LED	XP-E	cd/Im	1.100
Color	Clear	Gerber File	Available
Diameter	19.6 +15.4 mm		
Height	10.5 mm		
Style	Rectang		
Optic Material	PMMA		
Holder Material	-		
Fastening	-		
Status	Ready		

Ordering number CA10823 Description 1

Family	Strada-A	FWHM	68+136 degrees
Type	Assembly	Efficiency	93 %
LED	XP-E	cd/Im	1.100
Color	Clear	Gerber File	Available
Diameter	19.6 +15.4 mm		
Height	10.65 mm		
Style	Rectang		
Optic Material	PMMA		
Holder Material	-		
Fastening	-		
Status	Ready		




PRODUCT DATASHEET

Strada-A series

last update 15/2/2013

NOTE: The typical divergence will be changed by different color, chip size and chip position tolerance. The typical total divergence is the full angle measured where the luminous intensity is half of the peak value.

Relative intensity of CA10823_Strada-A-XP-tape

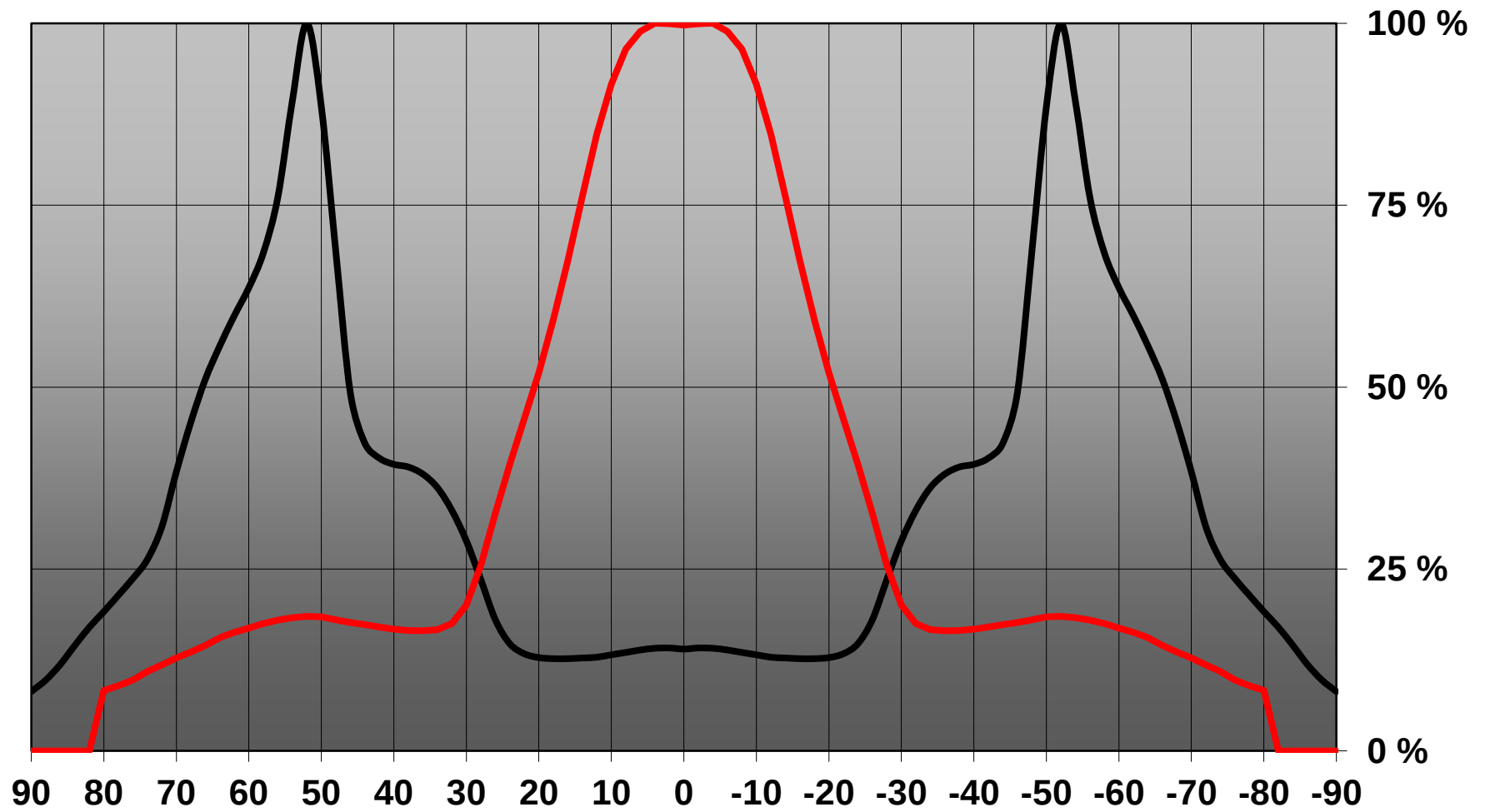

D

C




B

A

4

4

Tape 0.4mm

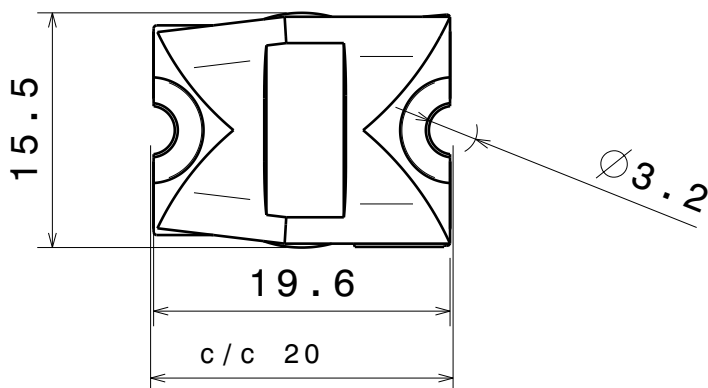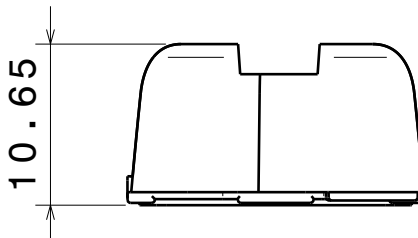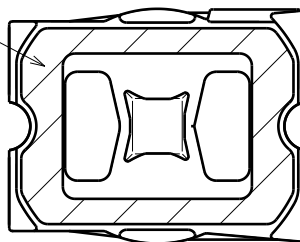

Material:
Lens PMMA
Tape PU foam with PSA

This drawing is our property.
It can't be reproduced
or communicated without
our written agreement.



L
T
F
F

e
e
l
i
n
N

d
h

DRAWING TITLE

Datasheet Strada-A-XP assy

DRAWN BY

DATE

05.08.2011

CHECKED BY

DATE

07.07.2011

DESIGNED BY

DATE

20.11.2008

SIZE

A4

DRAWING NUMBER

REV

1

SCALE

2:1

WEIGHT (g)

SHEET

1/1

D

A

1

1