



**78207-110HLF - DUBOX™,Basics+ : 2
Wall Shrouded Header - Through Hole -
Double row - 10 Positions 2.54 mm - Right
Angle**

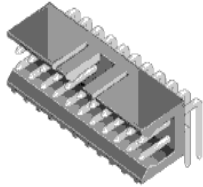

www.fci.com

Mating Half

 65846-010LF

Specifications

Approvals / Certifications	
UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved
Dimensional	
Length (Mating pin)	5.84 mm (0.23 in.)
Length (Tail)	3.5 mm (0.12 in.)
Electrical	
Current rating	3A Continuous
Resistance (Insulation)	100000 M-ohms
Voltage rating	1000V rms
General	
Number of contacts	10
Number of rows	2
Orientation	Right Angle
Product Type	Shrouded Header
Housing Style (Double row)	65846 65043
Housing Style (Single row)	78211 65039
Polarization (Key)	Yes
Mating half	Mates with PV CTW Housings and Contacts
Series Number	78207
Mounting	
Mounting style	Through Mount
Solder process	Wave Soldering
Other Features	
Packaging (Type)	Bulk
Physical	
Color (Housing)	Black

Material (Contact)	Phosphor Bronze
Material (Housing)	Thermoplastic
Plating (Contact area)	0.76 μm (30 $\mu\text{in.}$) Gold
Plating (Tail)	0.76 μm (30 $\mu\text{in.}$) Gold
Underplating	1.27 μm (50 $\mu\text{in.}$) Nickel
Temperature (Operating - range)	-40°C to +95°C