


P409, Film, Metallized Paper, Resistor/Capacitor, 0.047 uF, 20%, 630 VDC, 85°C, Lead Spacing = 15.2mm

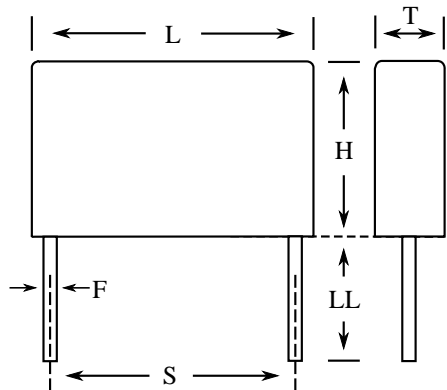

General Information	
Supplier:	KEMET
Series:	P409
Dielectric:	Metallized Paper
Style:	Radial
Features:	RC Unit approved
RoHS:	Yes
Lead:	Wire Leads
Qualifications:	ENEC, UL, cUL
Construction:	Molded
Miscellaneous:	Resistor Tolerance: +/-30%. Resistor= 100 Ohms

Dimensions	
L	18.5mm MAX
H	13mm MAX
T	7.3mm MAX
S	15.2mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

Specifications	
Capacitance:	0.047 uF
Capacitance Tolerance:	20%
Voltage AC:	275 VAC
Voltage DC:	630 VDC
Temperature Range:	-40/+85C
Rated Temperature:	85°C
Insulation Resistance:	3 GOhms
Safety Class:	X2

Packaging Specifications	
Packaging:	Bulk, Bag
Packaging Quantity:	400