



ENGLISH


## Datasheet

# AC Axial Fan, 254 Dia. x 88.9mm, 929m<sup>3</sup>/h, 35W, 230 V ac (OA254 Series)

RS Stock 619-6949



### Dimensions: (mm)

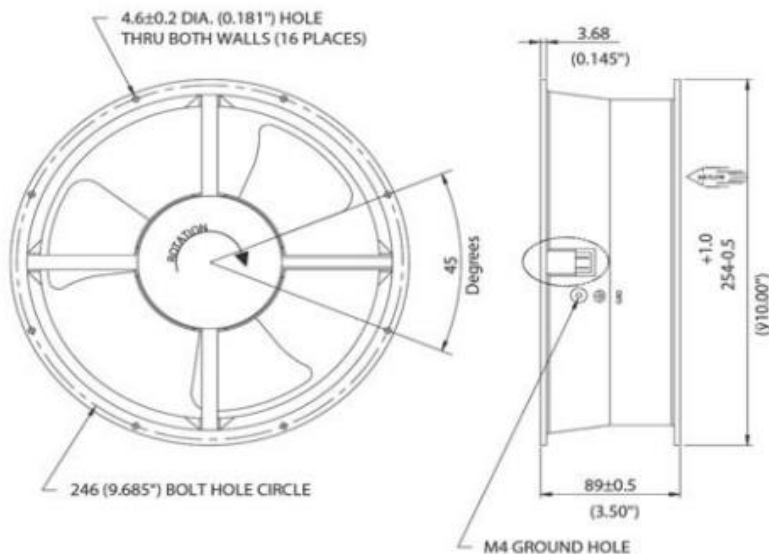



### Specifications

- Frame: Die cast Aluminium
- Impeller: PBT , UL94V-0 Thermoplastic
- Motor: High Performance Capacitor Drive, Thermally Protected
- DIELECTRIC STRENGTH :1 minute@1500 VAC, 50/60 Hz
- LIFE EXPECTANCY (L10) :Ball Bearing 60,000 Hours
- Operating Temperature :-20C ~ +80C
- Safety Approvals: UL/CUL, TUV, CE

RS Part No.	Orion Part No.	Speed	Airflow	Noise	Volts	Voltage	Current	Connection Type
6196927	OA254AP-11-1WB	1650	547	55	115	80~130	35	Wire
6196949	OA254AP-22-1WB	1650	547	55	230	160~260	35	Wire