

Classic ECO Ball

CLAS.ECO BALL 42W B22 240V SLV

0023114

Range features



PRODUCT OVERVIEW

| | |
|----------------------------|---------------|
| Ordering number | 0023114 |
| Light colour | 828 Homelight |
| Technology | Halogen |
| Energy class | D |
| Average life (Rated) (h) | 2000 |
| Lamp finish | Clear |
| Lamp shape | Ball |
| Dimmable | Yes |
| Cap/Base | B22 |
| Type | Ball ECO |
| EAN code | 5410288231143 |
| CRI (Ra) | 100 |
| Beam angle(°) | na |
| Colour temperature (K) | 2800 |
| Luminous flux (Rated) (lm) | 600 |
| Watt (Nominal) (W) | 42 |
| Equivalent watt (W) | 53 |
| Voltage (V) | 240 |

Classic ECO Ball

CLAS.ECO BALL 42W B22 240V SLV

0023114

DATA TABLE

General data

| | |
|---|--------------------------------|
| Ordering number | 0023114 |
| Technology | Halogen |
| Average life (Nominal) (h) | 2000 |
| Average life (Rated) (h) | 2000 |
| Energy saving lamp | No |
| Energy class | D |
| Lamp shape | Ball |
| Lamp finish | Clear |
| Dimmable | Yes |
| Cap/Base | B22 |
| Type | Ball ECO |
| EAN code | 54 10288231143 |
| Product name | CLAS.ECO BALL 42W B22 240V SLV |
| Lamp mercury content (mg) | 0 |
| Starting time (max) (s) | 0.01 |
| Warm-up time to 60% of full light (max) (s) | Instant full light |
| Control gear required | No |
| Fixture rating | Open |
| IEC Reference | IEC 60357 |
| IEC Reference 2 | IEC 60432-2 |
| Intended purpose | General lighting |
| No. of switching cycles before premature failure (min) | > 8000 |
| Special purpose lamp | No |
| Transformer required | No |
| Sales pack quantity | 10 |
| Optimal operating condition (°C) | 25 |

Optical data

| | |
|---|---------------|
| Light colour | 828 Homelight |
| CRI (Ra) | 100 |
| Suitable for accent lighting | No |
| Beam angle(°) | na |
| Colour temperature (K) | 2800 |
| Luminous flux (Rated) (lm) | 600 |
| Lumen maintenance at end of nominal life (%) | 80 |
| Luminous flux (Nominal) (lm) | 600 |

Classic ECO Ball

CLAS.ECO BALL 42W B22 240V SLV

0023114

Electrical data

| | |
|--|-----|
| kWh per 1000 hours burning time | 42 |
| Watt (Rated) (W) | 42 |
| Watt (Nominal) (W) | 42 |
| Equivalent watt (W) | 53 |
| Voltage (V) | 240 |
| Lamp power factor | 1 |

Physical data


| | |
|-------------------------------------|------|
| Lamp Length (mm) - C/L | 72.5 |
| Lamp Diameter (mm) - D | 46 |
| Packaging outer width (cm) | 25 |
| Packaging outer length (cm) | 48.5 |
| Packaging outer height (cm) | 17.5 |
| Packaging single width (cm) | 4.55 |
| Packaging single length (cm) | 4.55 |
| Packaging single height (cm) | 7.6 |

Classic ECO Ball

CLAS.ECO BALL 42W B22 240V SLV

0023114

TECHNICAL DRAWINGS

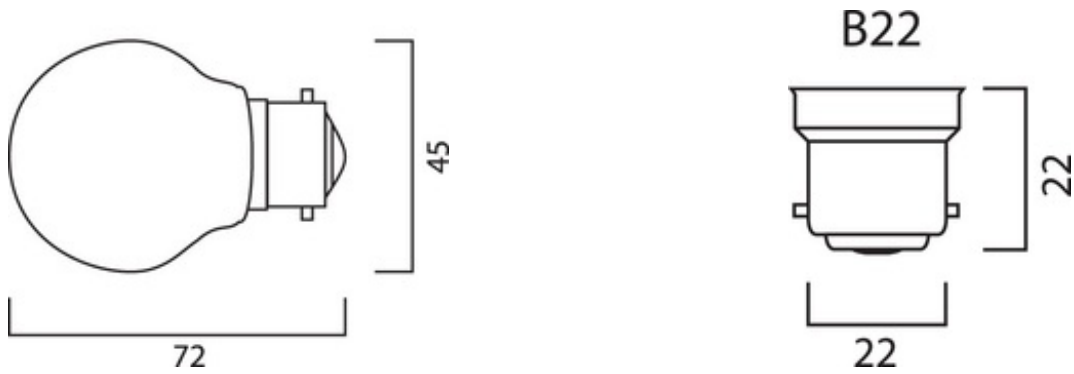

ENERGY LABEL

