



322 R

Reversible screwdriver for slot-head and PHILLIPS® screws

- Ergonomic bimaterial grip
- Chrome Vanadium steel blade
- Chrome plated finish with sandblasted tip

axbxc mm	n°xc	L mm	code	
1x6x75	2x75	200	03220097	1




323 RV

Empty holders for screwdrivers

- For screwdrivers 322-324
- Enamelled sheet steel

n°	L mm	code	
7	205	Q323511	1
10	295	Q323512	1
13	390	Q323513	1

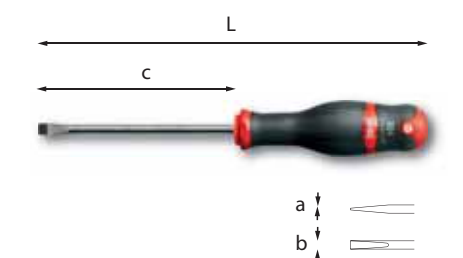

324

UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

axbxc mm	L mm	code	
0,5x3x75	169	03240001	5
0,5x3x100	194	03240002	5
0,8x4x100	204	03240003	5
0,8x4x125	229	03240004	5
0,8x4x150	254	03240005	5
1x5,5x100	209	03240006	5
1x5,5x125	234	03240007	5
1x5,5x150	259	03240008	5
1,2x6,5x125	245	03240009	5
1,2x6,5x150	270	03240010	5
1,2x8x200	325	03240011	5
1,6x10x200	325	03240012	5
2x12x250	375	03240013	1




324 SE6

Set of six screwdrivers for slot-head screws

- 324 D/0,4x2,5x50-0,5x3x75-0,6x3,5x100
- 324/0,8x4x100-1x5,5x125-1,2x6,5x150

g	code	
460	03240252	1

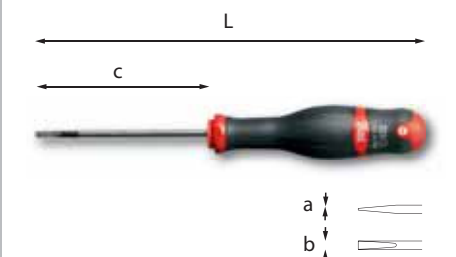


324 D

UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- For driving recessed studs or screws
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

axbxc mm	L mm	code	
0,4x2,5x50	144	03240026	5
0,5x3x75	169	03240027	5
0,6x3,5x100	204	03240028	5
0,8x4x100	204	03240029	5
0,8x4x150	254	03240030	1
1x5,5x125	234	03240031	5
1x5,5x150	259	03240032	1
1,2x6,5x150	270	03240033	1

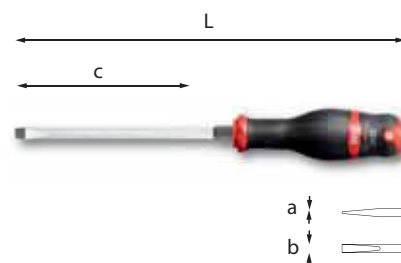


324 E

UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- Model with hexagonal drive and hexagonal blade for powerful tightening, also with a wrench
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

axbxc mm	L mm	code	
0,8x4x100	204	03240116	1
1x5,5x125	234	03240117	1
1,2x6,5x150	270	03240096	1
1,2x8x175	300	03240097	1
1,6x8x175	300	03240098	1
1,6x10x175	300	03240099	1
2x12x250	375	03240100	1

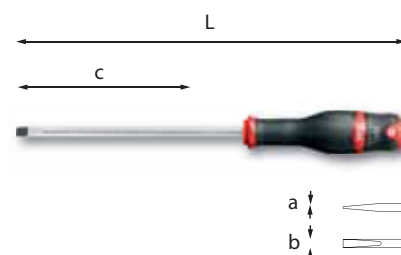


324 L

UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- Model with long blade
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

axbxc mm	L mm	code	
0,6x3,5x250	354	03240019	1
0,8x4x300	404	03240020	1
1x5,5x300	409	03240021	1

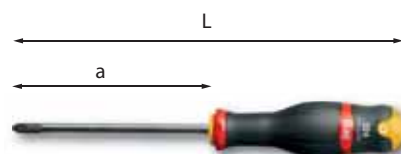

324 PH

UNI ISO 8764 DIN 5260

Screwdrivers for Phillips® screws

- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	code	
0x75	179	03240039	5
1x75	184	03240040	5
1x100	209	03240041	5
2x100	220	03240042	5
2x125	245	03240043	5
3x150	275	03240044	5
4x200	325	03240045	1




324 PH/SE4

Set of four screwdrivers for slot-head and PHILLIPS® screws

- 324 PH/0x75-1x75-2x100-3x150

n°xa	L mm	code	
530	03240268	1	

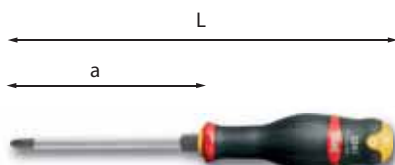


324 EPH

UNI ISO 8764 DIN 5260

Screwdrivers for Phillips® screws

- Model with hexagonal drive and hexagonal blade for powerful tightening, also with a wrench
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	mm	code	
1x100	209	8	03240121	1
2x125	245	10	03240104	1
3x150	275	12	03240105	1
4x200	325	14	03240106	1

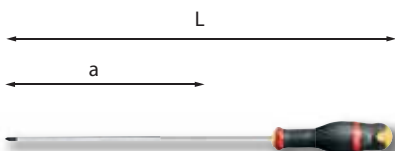


324 LPH

UNI ISO 8764 DIN 5260

Screwdrivers for Phillips® screws

- Model with long blade
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	code	
1x250	359	03240050	5
2x250	370	03240051	5

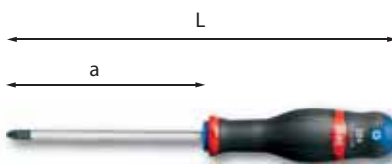


324 PZ

UNI ISO 8764 DIN 5260

Screwdrivers for POZIDRIV®-SUPADRIV® screws

- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	code	
0x75	179	03240056	1
1x75	184	03240057	1
2x100	220	03240058	1
3x150	275	03240059	1

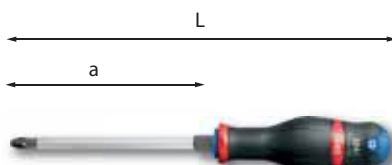


324 EPZ

UNI ISO 8764 DIN 5260

Screwdrivers for POZIDRIV®-SUPADRIV® screws

- Model with hexagonal drive and hexagonal blade for powerful tightening, also with a wrench
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	mm	code	
2x125	245	10	03240110	1
3x150	275	12	03240111	1
4x200	325	14	03240112	1

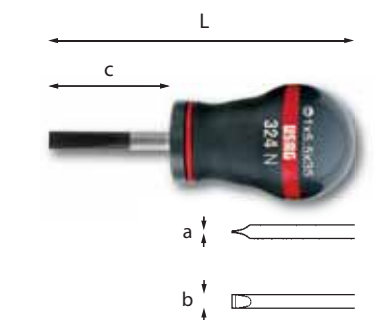


324 N

UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- Stubby model
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

axbxc mm	L mm	code	
0,8x4x35	91	03240063	5
1x5,5x35	91	03240064	5
1,2x6,5x35	91	03240065	5

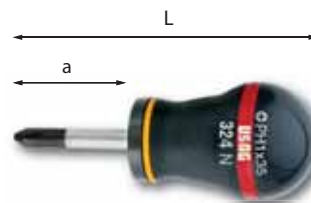

324 NPH

UNI ISO 8764 DIN 5260

Screwdrivers for Phillips® screws

- Stubby model
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	code	
1x35	91	03240068	5
2x35	91	03240069	5



324 SH8

Set of eight screwdrivers for slot-head and PHILLIPS® screws

- 324 D/0,4x2,5x50
- 324/0,5x3x75-0,8x4x100-1x5,5x125-1,2x6,5x150
- 324 PH/0x75-1x75-2x100

n°xa	L mm	code	
640	03240250	1	



324 SH10

Set of ten screwdrivers for slot-head and PHILLIPS® screws

- 324 D/0,4x2,5x50-0,5x3x75-0,6x3,5x100
- 324/0,8x4x100-1x5,5x125-1,2x6,5x150
- 324 PH/0x75-1x75-2x100-3x150

n°xa	L mm	code	
890	03240255	1	




324 SH12

Set of twelve screwdrivers for slot-head, PHILLIPS® and POZIDRIV®-SUPADRIV® screws

- 324 D/0, 4x2, 5x50
- 324/0, 5x3x75-0, 8x4x100-1x5, 5x125-1, 2x6, 5x150
- 324 N/1x5, 5x35
- 324 PH/0x75-1x75-2x100
- 324 NPH/2x35
- 324 PZ/1x75-2x100

gr	code	
950	03240251	1

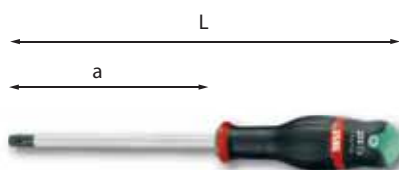

324 TX

Screwdrivers for TORX® screws

- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	code	
T6x50	145	03240071	5
T7x50	145	03240072	5
T8x50	145	03240073	5
T9x75	170	03240074	5
T10x75	179	03240075	5
T15x75	184	03240076	5
T20x100	220	03240077	5
T25x100	220	03240078	5
T27x100	220	03240079	1
T30x125	245	03240080	1
T40x150	275	03240081	1



324 TX/S7

Set of seven screwdrivers for TORX® screws

- 324 TX T10x75-T15x75-T20x100-T25x100-T27x100-T30x125-T40x150

gr	code	
810	03240264	1




324 TX/S11

Set of eleven screwdrivers for TORX® screws

- 324 TX T6x50-T7x50-T8x50-T9x50-T10x75-T15x75-T20x100-T25x100-T27x100-T30x125-T40x150

gr	code	
920	03240266	1

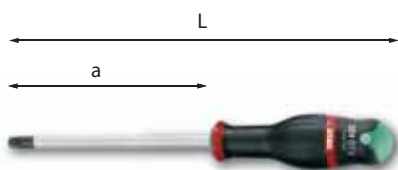

324 STX

Screwdrivers for TORX® Tamper Resistant® screws

- For safety screws
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	code	
T10x75	179	03240086	5
T15x75	184	03240087	5
T20x100	220	03240088	5
T25x100	220	03240089	5
T27x100	220	03240090	1
T30x125	245	03240091	1
T40x150	275	03240092	1




324 STX/S7

Set of seven screwdrivers for TORX® Tamper Resistant® screws

- 324 STX T10x75-T15x75-T20x100-T25x100-T27x100-T30x125-T40x150

gr	code	
810	03240093	1

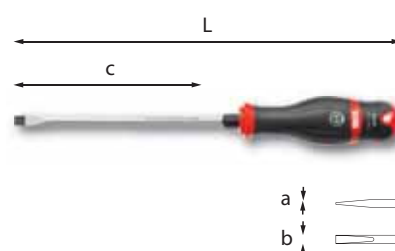


324 H

Screwdrivers for slot-head screws

- Model with hexagonal drive and hexagonal blade for powerful tightening, also with a wrench
- Metal rear dome to protect the beating zone
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

axbxc mm	L mm	mm	code	
0,8x4x100	204		03240133	1
1x5,5x125	234	8	03240134	1
1,2x6,5x150	270	10	03240135	1
1,2x8x175	300	11	03240136	1
1,6x10x175	300	12	03240137	1
2x12x200	300	14	03240138	1
2,5x14x250	375	14	03240139	1

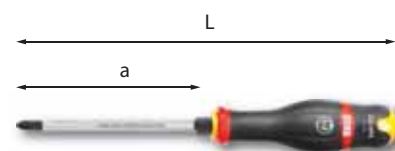

324 HPH

Screwdrivers for Phillips screws

- Model with hexagonal drive and hexagonal blade for powerful tightening, also with a wrench
- Metal rear dome to protect the beating zone
- Ergonomic three-material grip
- Special Silicon Chrome Manganese steel blade
- Chrome plated finish with burnished tip

n°xa	L mm	mm	code	
1x100	209	8	03240141	1
2x125	245	10	03240142	1
3x150	275	12	03240143	1