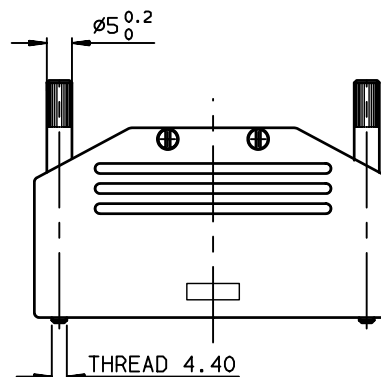
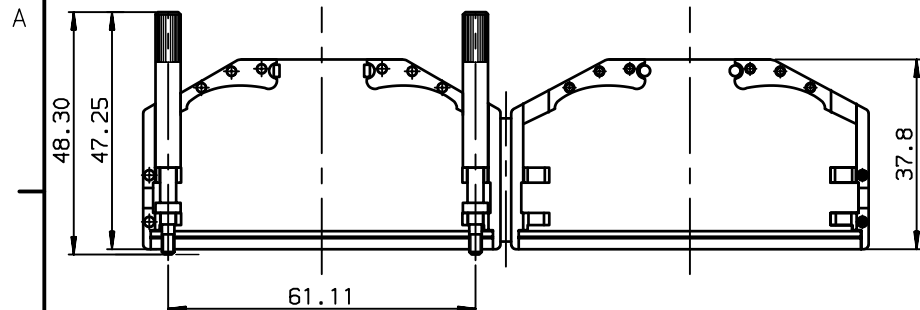


1

2

3

4

**MATERIAL:**

- hood: thermoplastic
- screws lock: brass
- strain relief: die cast + steel
- screws: steel


TEMPERATURE RANGE:

- Climatic category : -35°/ +95°



PACKAGING:

Box of 100 individual sets


B

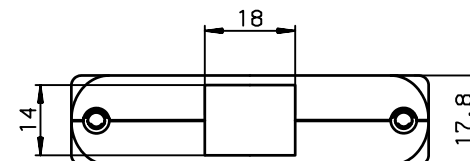

C

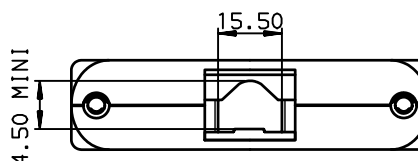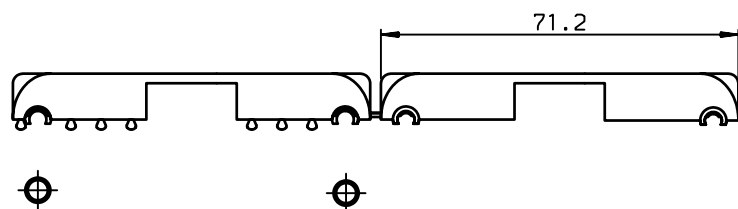


P/N: 86303641BLF

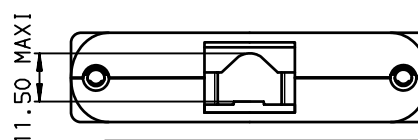**NOTE:RoHS INFORMATIONS**

- These products meet European union Directives and other country regulations as described in GS-22-008. (RoHS Compliant products)
- Packaging spec: see GS-14-920

European Views

D

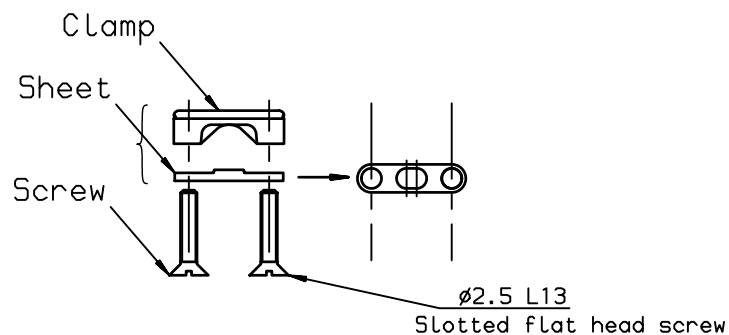

SCALE: 2

rev	ecn no	dr	date
E	-	MPE	2004/09/16
F	LS05-0026	MPE	2005/07/08
G	LS05-0084	MPE	2005/09/29
H	LS06-0095	LGO	2006/07/24
J	LS07-0253	MPE	2007/10/09
-	-	-	-
-	-	-	-

www.fciconnect.com			surface ISO 1302		tolerance std ISO 406 ISO 1101		projection 		mm 	
			TOLERANCES UNLESS OTHERWISE SPECIFIED							
Dr	BART	2004/04/14	ANGULAR LINEAR		0.X	±0.1	size A3	Scale 1		
Eng	PESSON	2004/04/14			0.XX	±0.1				
Chr	LEGARE	2004/04/14			0.XXX	±0.1				
Appr	LEGARE	2004/04/14	Product family				D-SUB	ECN LS07-0253		Spec ref -
			title SNAP TOGETHER				dwg no C01-8655-1582			Rev. J
catalog no			-				CUSTOMER			sheet 1 of 1

REV F - 2006-04-17

1

2

3

4