


Deep groove ball bearings, single row, shield on both sides

Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
15	24	5	1,56	0,8	0,034	60000	30000	0,0074	61802-2Z

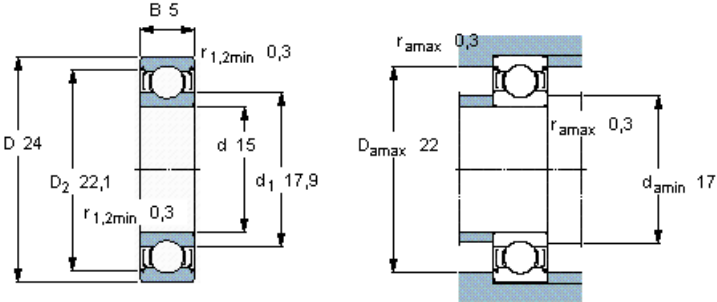

Calculation factors

$k_r$  0,015  
 $f_0$  10